

Actuator guide kit



 

UGCG

Guide shaft

- Allows the assembly of customised length actuator guides with 1-4 guide shafts
- For short or long bearings
- Material: Hardened ground steel XC55

Excellent price
Quality/ratio

Hardened steel

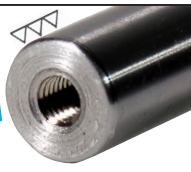

DISCOUNTS

Qty	1+	2+	4+
Disc.	List -5%		On request

Part number	ØC (h6)	L (mm)	ØM1	ØM2	Weight (kg)	Price each
UGCG10-127	10	127	M5	M5	0,08	24,29 €
UGCG10-152	10	152	M5	M5	0,09	25,01 €
UGCG10-177	10	177	M5	M5	0,11	25,79 €
UGCG10-227	10	227	M5	M5	0,14	27,26 €
UGCG10-277	10	277	M5	M5	0,17	28,77 €
UGCG10-327	10	327	M5	M5	0,20	30,24 €
UGCG12-164	12	164	M5	M6	0,15	26,66 €
UGCG12-189	12	189	M5	M6	0,17	27,64 €
UGCG12-239	12	239	M5	M6	0,21	29,52 €
UGCG12-299	12	299	M5	M6	0,27	31,81 €
UGCG12-339	12	339	M5	M6	0,30	33,32 €
UGCG12-389	12	389	M5	M6	0,35	35,21 €
UGCG12-459	12	459	M5	M6	0,41	37,89 €
UGCG16-182	16	182	M6	M6	0,29	32,84 €
UGCG16-207	16	207	M6	M6	0,32	34,03 €
UGCG16-257	16	257	M6	M6	0,40	36,42 €
UGCG16-317	16	317	M6	M6	0,50	39,25 €
UGCG16-357	16	357	M6	M6	0,56	41,20 €
UGCG16-407	16	407	M6	M6	0,64	43,54 €
UGCG16-477	16	477	M6	M6	0,75	46,88 €
UGCG16-557	16	557	M6	M6	0,87	50,70 €
UGCG20-232	20	232	M8	M8	0,57	37,75 €
UGCG20-282	20	282	M8	M8	0,69	40,47 €
UGCG20-342	20	342	M8	M8	0,84	43,72 €
UGCG20-382	20	382	M8	M8	0,94	45,92 €
UGCG20-432	20	432	M8	M8	1,06	48,62 €
UGCG20-502	20	502	M8	M8	1,23	52,46 €
UGCG20-582	20	582	M8	M8	1,43	56,82 €
UGCG20-682	20	682	M8	M8	1,67	62,27 €
UGCG25-286	25	286	M10	M10	1,10	49,83 €
UGCG25-336	25	336	M10	M10	1,29	53,10 €
UGCG25-396	25	396	M10	M10	1,52	56,98 €
UGCG25-436	25	436	M10	M10	1,67	59,87 €
UGCG25-486	25	486	M10	M10	1,86	62,83 €
UGCG25-556	25	556	M10	M10	2,13	67,42 €
UGCG25-636	25	636	M10	M10	2,44	72,62 €
UGCG25-736	25	736	M10	M10	2,82	79,13 €

Dimensions in mm

Our other products



GGB

Female wing knob,
With blind thread



PMC48_M8

Anti-vibration
machine mount, Oval
base plate



PTKss

Foot for the food
industry, Stainless
steel - 3-A standard



GPB

Threaded spherical
knob, Moulded thread



PRF_ROUL_F

Castor for aluminium
profile, With brake



MAX26

Motor-gearbox 12V
and 24V DC, from
0,075 to 0,6Nm



Q6

Deep groove ball
bearing, Steel



PRF_ER

Joining bar for
aluminium profile,
joint bar



UFX

Spare tyre UNEFLEX®
coupling, range



DILC

Indexing plunger with
cam, with cam



FHCSS

Countersunk screw,
Stainless steel A2 -
DIN 7991



PTA40

Articulated foot with
solid base foot Ø 40,
3000N

Complementary products



UGPC

Actuator guide kit,
Short bearing



UGPL

Actuator guide kit,
Long bearing



ZAm

Shaft for linear
guides, Hardened
ground steel



ZA

Shaft for linear
guides, Hardened
ground steel