

H Type guide unit







UGH16 For $\text{Ø}12 + \text{Ø}16$ actuators (ISO 6432)

- Guide system for actuator
- Fitted with 4 smooth bronze bearings
- Slides protected by wiper joints
- Actuator coupling available on front face
- Supplied with fixing screw for actuator
- Maintenance free
- Working temperature: +5 to +80 °C
- Maximum speed: 1 m/s
- Maximum loads: See end of section
- Material:

Body + face plate:
anodised aluminium
Couplings + screws:
Zinc plated steel
Guide shafts:
Chromed steel

Excellent price/
Quality ratio

Accurate even over
long strokes

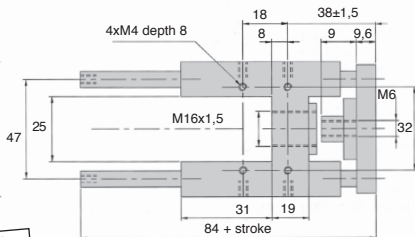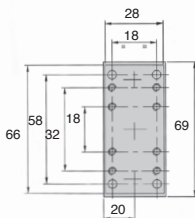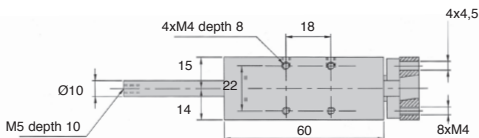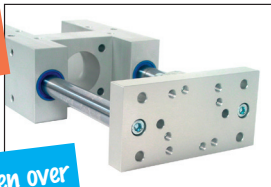

DISCOUNTS

Qty	1+	2+
Disc.	List	On request

Part number	Stroke	Ø Actuator	Ø Guide rod	Weight (kg)	Price each
UGH16-25	25	12 et 16	10	0,43	183,01 €
UGH16-50	50	12 et 16	10	0,46	183,97 €
UGH16-100	100	12 et 16	10	0,52	185,88 €
UGH16-160	160	12 et 16	10	0,59	188,15 €
UGH16-200	200	12 et 16	10	0,64	189,67 €
UGH16-250	250	12 et 16	10	0,70	191,63 €

Dimensions in mm

Our other products



ETQ
Magnetic label holder for aluminium profile, Label holder



SRG
Adjustable latch clamp with strike plate, Stroke from 117,4mm to 128mm



CHAC4040NP
Square hinge with riveted pin, not drilled, Square with riveted pin,...



RLX
Free running conveyor roller, PVC



PRF_ART
Articulated bracket for use with aluminium profile, With clamping ha...



LVT
Miniature motorised actuator 2A, 2 amperes



BC2
Panamech, Multi-Beam, Aluminium - with clamping jaw



CHM110
Worm and wheel gear reducer, up to 980 Nm




HRV
V-rail guidance Simple Select® system, Rail with



VTLF
3 lobed handle, Polyamide - Brass



 DOMI50
Connecting kits, XZ linking kit



PM3
Worm and wheel set, Machined plastic (delrin)

Complementary products