

H Type guide unit



UGH20





For **Ø20** actuators (ISO 6432)

- Guide system for actuator
- Fitted with 4 smooth bronze bearings
- Slides protected by wiper joints
- Actuator coupling available on front face
- Supplied with fixing screw for actuator
- Maintenance free
- Working temperature: +5 to +80 °C
- Maximum speed: 1 m/s
- Maximum loads: See end of section
- Material:

Body + face plate:
anodised aluminium
Couplings + screws:
Zinc plated steel
Guide shafts:
Chromed steel

**Excellent price/
Quality ratio**

**Accurate even over
long strokes**

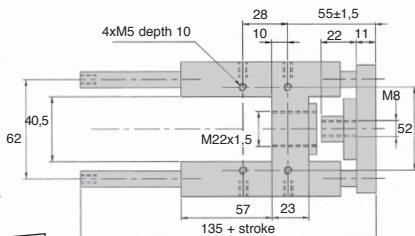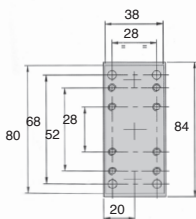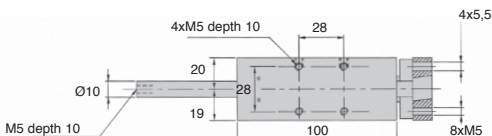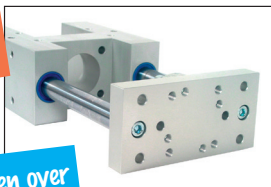

DISCOUNTS

Qty	1+	2+
Disc.	List	On request

Part number	Stroke	Ø Actuator	Ø Guide rod	Weight (kg)	Price each
UGH20-25	25	20	10	0,93	201,98 €
UGH20-50	50	20	10	0,96	202,91 €
UGH20-100	100	20	10	1,02	204,78 €
UGH20-160	160	20	10	1,09	207,07 €
UGH20-200	200	20	10	1,14	208,66 €
UGH20-250	250	20	10	1,20	210,54 €

Dimensions in mm

Our other products



BoWex® curved tooth gear coupling, Nylon



Spur gear - precision range, Pre-hardened Steel 35NCD6



V-rail guidance Simple Select® system, Rail with carriage



Pressed stainless steel flange bearing, Stainless steel



Male clevis end, Stainless steel short



Assorted feeler strips, Assorted feeler strips



 
Friction clutch, 190 to 1800 Nm



Single housed bearing, Bearing fitted with adhesive



Steel leadscrew, Medium carbon steel - 2 threads



RPP type belt per metre, RPP14 Steel cored polyurethane



Multifunction display, Articulated support



Spur gear - precision range, Pre-hardened Steel 35NCD6

Complementary products