

H Type guide unit



UGH20





For **Ø20** actuators (ISO 6432)

- Guide system for actuator
- Fitted with 4 smooth bronze bearings
- Slides protected by wiper joints
- Actuator coupling available on front face
- Supplied with fixing screw for actuator
- Maintenance free
- Working temperature: +5 to +80 °C
- Maximum speed: 1 m/s
- Maximum loads: See end of section
- Material:

Body + face plate:
anodised aluminium
Couplings + screws:
Zinc plated steel
Guide shafts:
Chromed steel

**Excellent price/
Quality ratio**

**Accurate even over
long strokes**

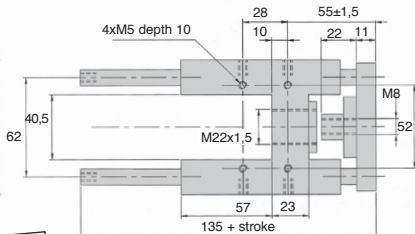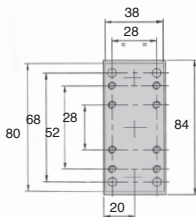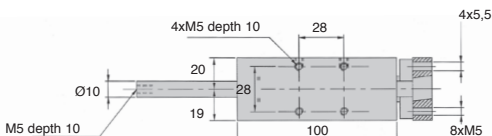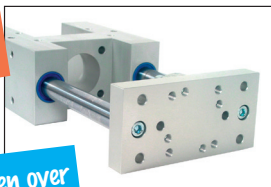

DISCOUNTS

Qty	1+	2+
Disc.	List	On request

Part number	Stroke	Ø Actuator	Ø Guide rod	Weight (kg)	Price each
UGH20-25	25	20	10	0,93	201,98 €
UGH20-50	50	20	10	0,96	202,91 €
UGH20-100	100	20	10	1,02	204,78 €
UGH20-160	160	20	10	1,09	207,07 €
UGH20-200	200	20	10	1,14	208,66 €
UGH20-250	250	20	10	1,20	210,54 €

Dimensions in mm

Our other products



HCA
Magnetic screw with
socket, Steel



PCS6ECO
Chain sprocket - steel,
6mm (DIN 04-1)



PX_PO
Carrying handle,
standard



PTKFss
Fixable foot for the
food industry,
Stainless steel - 3-A
standard



EX
Optional shaft for E-
type gear reducers, E
Gearboxes single
sided ou...



PFC
Fixed rubber levelling
foot, Levelling support
for small parts



SBF
Sealed flange bearing
unit for Food Industry,
cover



PCF4
Conical flexible
mount, Square base
plate



MPB
Hexagonal spacer,
Brass



PCS_PA6
Plastic sprocket,
9.525mm (DIN 06B-1)



VHTM
Hexagonal headed
screw Hygienic



LRR
Spring loaded latch,
Spring loaded latch

Complementary products