

# H Type guide unit



## UGH20





For **Ø20** actuators (ISO 6432)

- Guide system for actuator
- Fitted with 4 smooth bronze bearings
- Slides protected by wiper joints
- Actuator coupling available on front face
- Supplied with fixing screw for actuator
- Maintenance free
- Working temperature: +5 to +80 °C
- Maximum speed: 1 m/s
- Maximum loads: See end of section
- Material:

Body + face plate:  
anodised aluminium  
Couplings + screws:  
Zinc plated steel  
Guide shafts:  
Chromed steel

**Excellent price/  
Quality ratio**

**Accurate even over  
long strokes**

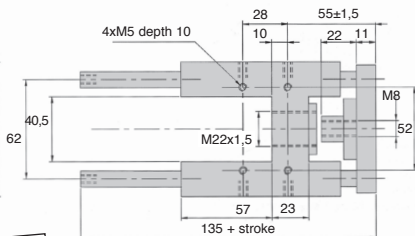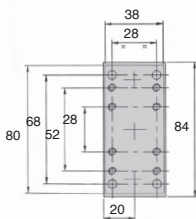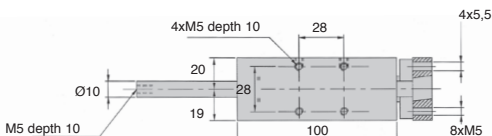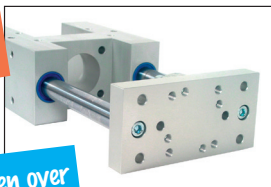

### DISCOUNTS

Qty	1+	2+
Disc.	List	On request

Part number	Stroke	Ø Actuator	Ø Guide rod	Weight (kg)	Price each
UGH20-25	25	20	10	0,93	201,98 €
UGH20-50	50	20	10	0,96	202,91 €
UGH20-100	100	20	10	1,02	204,78 €
UGH20-160	160	20	10	1,09	207,07 €
UGH20-200	200	20	10	1,14	208,66 €
UGH20-250	250	20	10	1,20	210,54 €

Dimensions in mm

## Our other products



DILC

Indexing plunger with cam, with cam



GB-RA

Brass spur gear, Brass CuZn39Pb3



PRF\_PF

Anchoring bracket for aluminium profile, Anchor



PSEC

Security pull handle, Thermoplastic



GMK17\_R

Round guide, Round guide for conical profile



SBS\_L

Chain link, Stainless steel



WINGbrEcrou

Manually tightened wing nut DIN315, Brass DIN 315



AZY\_SS

Stainless steel cylindrical elasto mount, Stainless steel



PRF\_VTM

Hammerhead screw, Hammerhead screw



TS01\_TW01

Drylin® T linear slide, up to 7000 N



TCC

Rigging screw (hook/hook), Steel



CHB

Worm and wheel gear reducer, up to 73 Nm

Complementary products