


H Type guide unit



UGH25

For **Ø25** actuators ISO 6432




- Guide system for standard pneumatic actuators
- Fitted with 4 smooth bronze bearings
- Slides protected by wiper seals
- Actuator coupling supplied
- Maintenance free
- Working temperature: +5°C to +80°C
- Maximum speed: 1 m/s
- Maximum loads : See end of section

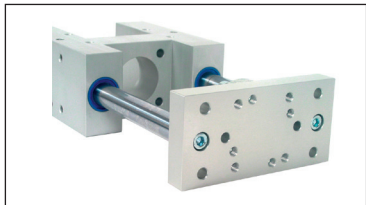

Material

- Body + face plate: anodised aluminium
- Couplings + screws: Zinc plated steel
- Shafts: Chromed steel

Accurate even for long strokes

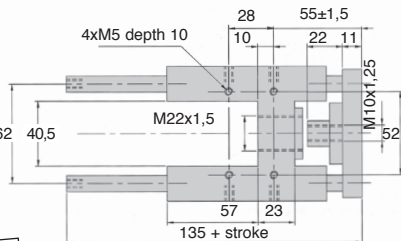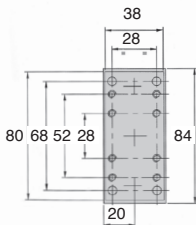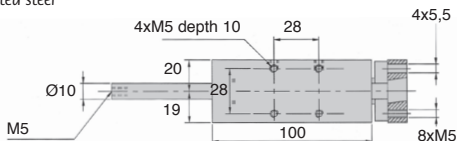

DISCOUNTS

Qty	1+	2+
Disc.	List	On request

Part number	Stroke (mm)	Actuator Ø (mm)	Guide rod Ø (mm)	Weight (kg)	Price each
UGH25-25	25	25	10	0,93	201,98 €
UGH25-50	50	25	10	0,96	202,89 €
UGH25-100	100	25	10	1,02	204,78 €
UGH25-160	160	25	10	1,09	207,07 €
UGH25-200	200	25	10	1,14	208,64 €
UGH25-250	250	25	10	1,20	210,52 €

Dimensions in mm

Our other products




PFC

Fixed rubber levelling foot, Levelling support for small parts



TBE12

 Economic mini-table with trapezoidal leadscrew, 2kg



PF20NM

Worm and wheel gear reducer, up to 5 Nm



HAS

Captive C washer, Slotted flat headed shoulder screw



P40

Worm and wheel gear reducer, up to 18 Nm



PAPER

Handle for aluminium profile, Ergonomic handle



ESST

Tripod support base, Tripod support base



PRF4545

Standard aluminium profile, 45 x 45 mm



BOXKK

Boxed set of DIN6885A keys,




RFK58B

Hypoid gearbox - Stainless steel, up to



BSPM

Miniature ballscrew, Nut+rolled ballscrew

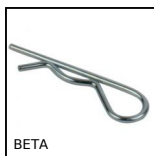

BETA

Hitch pin, Hitch

Complementary products