


H Type guide unit



UGH25

For **Ø25** actuators ISO 6432




- Guide system for standard pneumatic actuators
- Fitted with 4 smooth bronze bearings
- Slides protected by wiper seals
- Actuator coupling supplied
- Maintenance free
- Working temperature: +5°C to +80°C
- Maximum speed: 1 m/s
- Maximum loads : See end of section

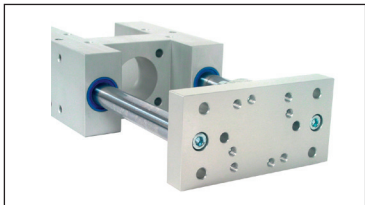

Material

- Body + face plate: anodised aluminium
- Couplings + screws: Zinc plated steel
- Shafts: Chromed steel

Accurate even for long strokes

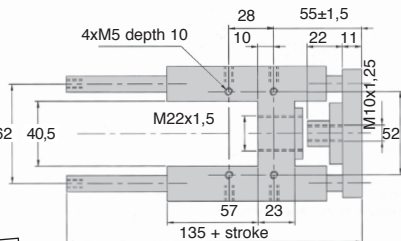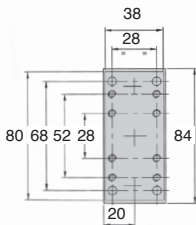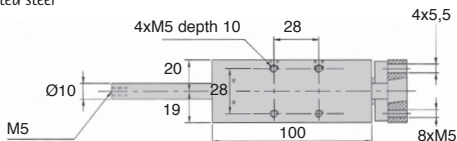

DISCOUNTS

Qty	1+	2+
Disc.	List	On request

Part number	Stroke (mm)	Actuator Ø (mm)	Guide rod Ø (mm)	Weight (kg)	Price each
UGH25-25	25	25	10	0,93	201,98 €
UGH25-50	50	25	10	0,96	202,89 €
UGH25-100	100	25	10	1,02	204,78 €
UGH25-160	160	25	10	1,09	207,07 €
UGH25-200	200	25	10	1,14	208,64 €
UGH25-250	250	25	10	1,20	210,52 €

Dimensions in mm

Our other products



VB

Small 6 lobe threaded handle - female, Duroplast - Stainless steel



PCF2

Conical flexible mount, Oval base plate



RFV50

Stainless steel worm and wheel gearbox, up to 80 Nm



PTA150

Articulated levelling foot, pressed base Ø150, Ø 150



CFES

Eccentric cam follower, Eccentric



PM4

Worm and wheel set, Bronze



PLM-20SC

Threaded cylindrical magnet, With threaded hole



MET

Cylindrical sintered bronze bush, Self-lubricating sintered bronze



PPG

Indexing plunger with flange, With horizontal mounting



YG1

HEAVY DUTY spur gear, Steel 35NCD6



BDMII

Magnetic bush for pin, Fast and light magnetic locking



PAV

Fixed anti-vibration foot mount, Vibration-dampening

Complementary products