


Actuator guide kit




UGPC

Short bearing, ball bushes



- Allows the assembly of short stroke actuator guides with 1-4 guide shafts
- Equipped with 2 ball bearings with wiper joints
- Material:
 - Body: anodised aluminium
 - Bearing housing: Plastic
 - Joint: Nitrile rubber
- Working temperature: +5°C to +80°C
- Maximum speed 2 m/s

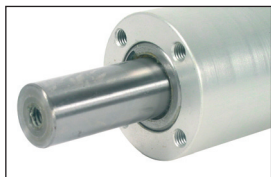

**Excellent price
Quality/ratio**

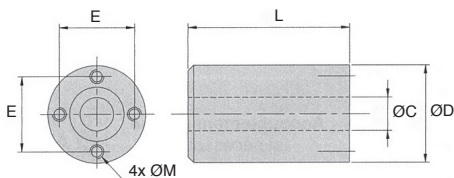

Load diagrams

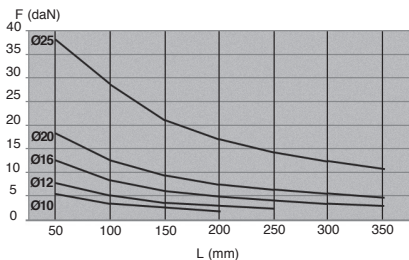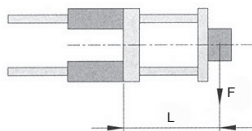

Loads given for a system with 2 guide rods



Dynamic or static load

DISCOUNTS

Qty	1+	2+	4+
Disc.	List	-5%	On request

Part number	ØC (Ø rod)	ØD	L	E	ØM	Weight (kg)	Price each
UGPC-10A	10	30	59	23	M4	0,10	68,55 €
UGPC-12A	12	35	63	27	M5	0,14	72,32 €
UGPC-16A	16	40	67	32	M5	0,18	82,51 €
UGPC-20A	20	50	75	39	M6	0,31	95,06 €
UGPC-25A	25	55	90	45	M6	0,44	115,67 €

Dimensions in mm

HPC

WEB
04/2020

www.hpceurope.com

Tél: 0 825 88 5000 Service 0,15€/min + prix appel

Our other products



PO

Pull handle - Multi-sector, Tapped recessed insert



TRMSS

Spur round rack, Stainless steel - module 1-5



DZYSS

Stainless steel cylindrical stop, stainless steel



H02SS

Needle roller universal joint - Stainless steel, Heavy duty DIN808-7...



ACL-PLAngle

Joining plate for aluminium profile, Angle connection



KH

Linear bearing, Light



PR65C

Half-articulated foot Ø 65, Ø 65



SLB

Indexing plunger, steel class 5.8



ZG0

Plastic spur gear, Machined plastic (delrin)



DB

Steel bevel gear, 2:1



GLT3-46

Telescopic drawer, Ø 65, Ø 65



BAG-MISS

Split shaft collar with clamp lever, Stainless steel

Complementary products



UGCG

Actuator guide kit, Long housing



UGPL

Actuator guide kit, Long bearing



UGAC_UGET

Actuator guide kit, Coupling for threaded cylinder end



UGAC_UGET

Connection for threaded actuator rod, Connection for threaded actuat...