


Actuator guide kit




UGPC

Short bearing, ball bushes



- Allows the assembly of short stroke actuator guides with 1-4 guide shafts
- Equipped with 2 ball bearings with wiper joints
- Material:
 - Body: anodised aluminium
 - Bearing housing: Plastic
 - Joint: Nitrile rubber
- Working temperature: +5°C to +80°C
- Maximum speed 2 m/s

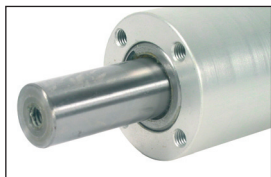

**Excellent price
Quality/ratio**

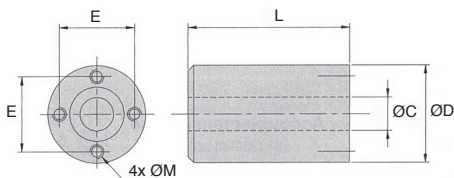

Load diagrams

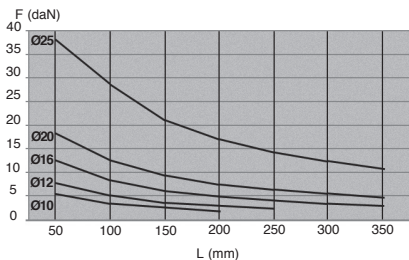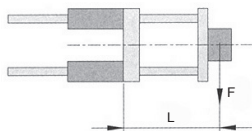

Loads given for a system with 2 guide rods



Dynamic or static load

DISCOUNTS

Qty	1+	2+	4+
Disc.	List	-5%	On request

Part number	ØC (Ø rod)	ØD	L	E	ØM	Weight (kg)	Price each
UGPC-10A	10	30	59	23	M4	0,10	68,55 €
UGPC-12A	12	35	63	27	M5	0,14	72,32 €
UGPC-16A	16	40	67	32	M5	0,18	82,51 €
UGPC-20A	20	50	75	39	M6	0,31	95,06 €
UGPC-25A	25	55	90	45	M6	0,44	115,67 €

Dimensions in mm


HPC

WEB
04/2020

www.hpceurope.com

Tél: 0 825 88 5000 Service 0,15€/min + prix appel

Our other products

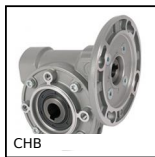

CHB

Worm and wheel gear reducer, up to 22 Nm



PLM-16A

Magnetic stud with threaded hole, With threaded hole



DOG111

Motor-gearbox 12V and 24V DC, from 1.5 to 6 Nm



RAG

Roller guide,



ZBconique

Machined plastic bevel gear, 1:1



TSM_T10M

T type timing belt per metre, T10 Steel cored polyurethane



PFM

Fixed levelling foot, Flanged plate



MO

Worm and wheel set, Machined plastic (delrin)



SDG_SS

Universal adjustable guide support bracket, Stainless



TCL-ECL

Support rod for heavy loads, Support spindle



PT821

Drive sprocket for slat top chain, Ranges 821 and 805



PRF_CHA

Hinge for aluminium profile, Surface mounting hinge

Complementary products



UGCG

Actuator guide kit, Long housing



UGPL

Actuator guide kit, Long bearing



UGAC_UGET

Actuator guide kit, Coupling for threaded cylinder end



UGAC_UGET

Connection for threaded actuator rod, Connection for threaded actuat...