



Actuator guide kit

Long bearing, ball bushes

UGPL



- Allows the assembly of short stroke actuator guides with 1-4 guide shafts
- Equipped with 2 ball bearings with wiper joints

- Material:


Body: anodised aluminium
Bearing housing: Plastic
Joint: Nitrile rubber

- Working temperature: +5°C to +80°C
- Maximum speed 2 m/s


Excellent price
Quality/ratio

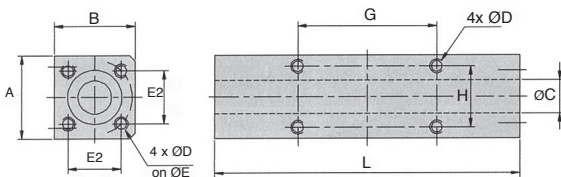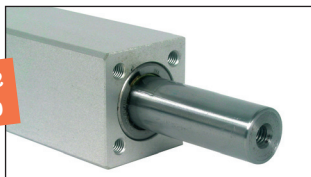

Load diagrams

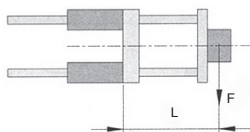

Loads given for a system with 2 guide rods

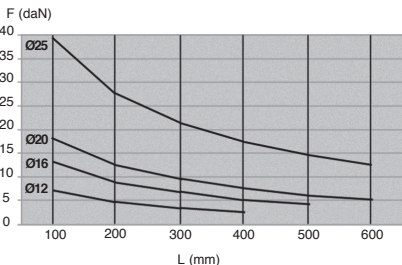

Dynamic or static load



DISCOUNTS

Qty	1+	2+	4+
Disc.	List	-5%	On request

Part number	ØC (Ø rod)	L	A	B	ØD	E	E2	G	H	Weight (kg)	Price each
UGPL-12A	12	110	30	29	M5	27	19,1	50	22	0,21	92,52 €
UGPL-16A	16	125	35	34	M5	32	22,6	60	27	0,30	104,50 €
UGPL-20A	20	140	40	39	M6	39	27,6	70	30	0,42	117,18 €
UGPL-25A	25	160	50	49	M6	45	31,8	80	38	0,78	142,92 €

Dimensions in mm

 
Our other products



HW_HT
Half-rail guide, Rail



CHAuss
Screwed hinge, 270°




LAT1
1A motorised linear actuator, 1 ampere



MC
Self-compensating shock-absorber, Self-compensating - without adjust...



 MEB
Moulded plastic bevel gear (nylon), 1:1



TPR
High helix leadscrew, Leadscrew only - up to 40mm per rotation



CHAK
Hi-Klik TM indent hinge, Hi-Klik™ - Detent hinge



PSPD40
Flexible tube handle, Black PVC



HLU
Spoked handwheel without handle,



PRES4HR
Manual workbench press, Force up to



PPS
Lifting ring, Universal threaded



PW_PWG25
Worm - precision range, Stainless steel

Complementary products



UGCG
Actuator guide kit, Long housing



UGPC
Actuator guide kit, Short bearing