



V shaped channel UtiliTrak®

Aluminium




UTKPWRR

- For use with UTK-PWCR roller carriages
- V shaped channel made from aluminium 6063-T6
- Lightweight
- Length may vary +/- 2mm

Option

- Max rail length : 3600mm

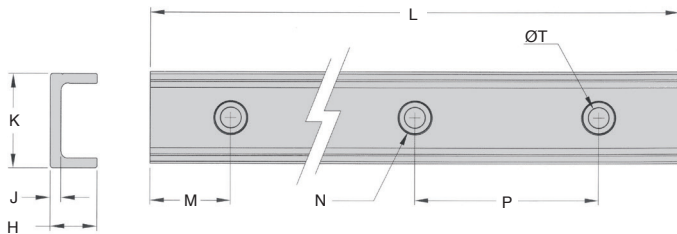

DISCOUNTS

Qty	1+	2+	4+
Disc. List	-10%		On request

Part number	H	J	K	L	M	Dia x depth (counterbore)	T (Ø hole)	P	Rail weight (kg/m)	Carriage weight (g)	Price each
UTK0-PWRR	11,0	4,0	20	1000	20	8,3 x 3	4,8	80	0,29	47	100,71 €
UTK1-PWRR	15,0	4,0	26	1000	20	9,8 x 2,8	5,8	80	0,43	94	109,79 €
UTK2-PWRR	19,7	4,5	40	1000	20	14,3 x 3	8,8	80	0,80	246	160,32 €

Dimensions in mm

Our other products



ZHBRA

Plastic bevel gear,
1,25:1 2:1 3:1



5H0

Parallel axis helical
gear, Machined plastic
(delrin)



PCS62

Chain sprocket - steel,
15.875 (DIN 10B-1)



CHAR5050_Z

Spring hinge, screwed



PRES

Manual workbench
press accessory for
PRES-3HR end
PRES-4HR, Set of s...



GBS

Nut for ballscrew,
Flanged ballscrew nut



J52

Spur gear coaxial
gearbox, from 0.27 to
0.90 Nm - Inline



RPCtcss

Swivel castor with
central hole, Stainless
steel - Polyamide -
with ...



HTD14M_85

HTD Heavy duty
timing pulley, HTD14



Q4

Double row radial
contact ball bearing,



CHB

Feet, For CHB gearbox



UTKswr

Utilitak® V rail, V rail

Complementary products



UTKpwcr

Utilitak® 3 wheels
carriage, Polymer
roller carriage



UTKpwr

Utilitak® V rail, V rail



UTKpwcr

Utilitak® 3 wheels
carriage, Polymer
roller carriage