



V shaped channel UtiliTrak®

Steel


HEPCO

UTKSWRR

- For use with STK-PWCR roller carriages
- Carbon bearing steel with hardened steel raceways
- Smoothness Ra 0.8µm
- Length may vary +/- 2mm

Option

- Max rail length : 3600mm

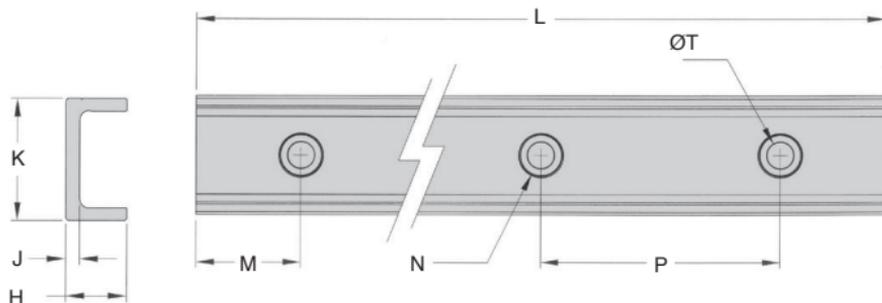

DISCOUNTS

Qty	1+	2+	4+
Disc. List	-10%	On request	

Part number	H	J	K	L	M	Dia x depth (counterbore) (Ø hole)	T (Ø hole)	P	Rail weight (kg/m)	Slide weight (g)	Price each
UTK1-SWRR	15,0	4,0	26	1000	20	9,8 x 2,8	5,8	80	1,33	121	266,56 €
UTK2-SWRR	19,7	4,5	40	1000	20	14,3 x 3	8,8	80	2,47	320	341,29 €
UTK3-SWRR	30,0	8,0	58	1000	20	14,3 x 5	8,8	80	5,36	910	505,79 €

Dimensions in mm

Fax: 0 825 88 6000 Service 0,15€/mln + prix appel

cial2@hpceurope.com

WEB
04/2020

HPC

Our other products



SHA_PT
Handwheel with handle, Polyamide



MSP23
Masterplate® glueable insert Ø23, Cylindrical Ø23 with threaded s...



SHS
Shoulder screw stainless steel 303, Stainless steel 303



PSG25
Spur gear - precision range, Pre-hardened Steel 35NCD6



SLBWSS
Indexing plunger, weldable, Weldable - Stainless steel



DBL820
Idler for slat top chain, Ranges 820 and 815



CHINV2
Invisible hinge, Invisible - Opening up to 125°



NPTF30
Fixed tube carrier, Fixed Ø14 to Ø20



PGNT
Thermoplastic T handle, With threaded spindle



SPIT
Floor mounting levelling plate, With anchoring point



RBGtc
Swivel castor with central hole, Steel - grey rubber



DOMI50
Domino 50 adjustable slide, Slide DOMILINE 50

Complementary products



UTKswcr
Utilitak® 3 wheels carriage, Steel roller carriage



UTKswr
Utilitak® V rail, V rail



UTKswcr
Utilitak® 3 wheels carriage, Steel roller carriage