



# V shaped channel UtiliTrak®

Steel


HEPCO

UTKSWRR

- For use with STK-PWCR roller carriages
- Carbon bearing steel with hardened steel raceways
- Smoothness Ra 0.8µm
- Length may vary +/- 2mm

## Option

- Max rail length : 3600mm

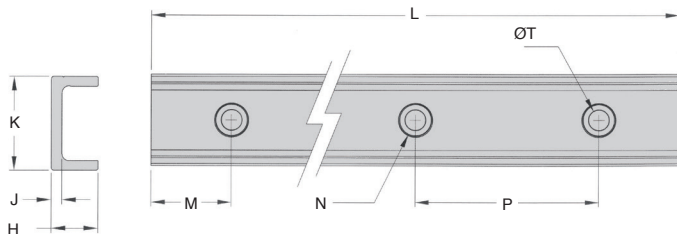

## DISCOUNTS

Qty	1+	2+	4+
Disc. List	-10%	On request	

Part number	H	J	K	L	M	Dia x depth (counterbore) (Ø hole)	T (Ø hole)	P	Rail weight (kg/m)	Slide weight (g)	Price each
UTK1-SWRR	15,0	4,0	26	1000	20	9,8 x 2,8	5,8	80	1,33	121	266,56 €
UTK2-SWRR	19,7	4,5	40	1000	20	14,3 x 3	8,8	80	2,47	320	341,29 €
UTK3-SWRR	30,0	8,0	58	1000	20	14,3 x 5	8,8	80	5,36	910	505,79 €

Dimensions in mm

## Our other products



BLHT60

Right angled gearbox, from 26 to 70 Nm




STRIP

Sealing brush strip, 3m length



gt64

 Rotating bent lever, Common applications



CHB

Worm and wheel gear reducer, up to 41 Nm



OP7

Mechanical digital position indicator, 5 numbers



BABPass

Hardened stainless steel ball pin with ring, With grip ring



CAP820

Slim slat top chain acetel, Narrow straight range 820



TMR

Rigid manual tensioner, Adjustable



BAG-MISS

Split shaft collar with clamp lever, Stainless



PSG08HC

Skive hobbed spur gears - precision



VBFP

Small 6 lobe threaded handle - female,



SFE

Female rod ends, Stainless steel / PTFE

## Complementary products



UTKswcr

Utilitak® 3 wheels carriage, Steel roller carriage



UTKswr

Utilitak® V rail, V rail



UTKswcr

Utilitak® 3 wheels carriage, Steel roller carriage