



# V shaped channel UtiliTrak®

Steel


HEPCO

UTKSWRR

- For use with STK-PWCR roller carriages
- Carbon bearing steel with hardened steel raceways
- Smoothness Ra 0.8µm
- Length may vary +/- 2mm

## Option

- Max rail length : 3600mm

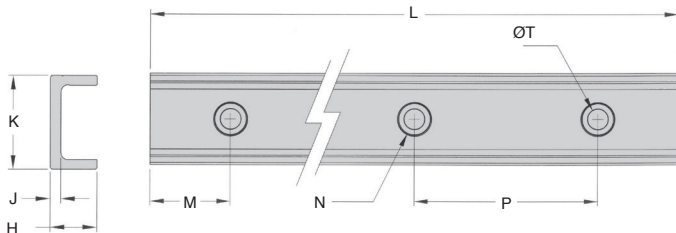

## DISCOUNTS

Qty	1+	2+	4+
Disc. List	-10%	On request	

Part number	H	J	K	L	M	Dia x depth (counterbore) (Ø hole)	T (Ø hole)	P	Rail weight (kg/m)	Slide weight (g)	Price each
UTK1-SWRR	15,0	4,0	26	1000	20	9,8 x 2,8	5,8	80	1,33	121	266,56 €
UTK2-SWRR	19,7	4,5	40	1000	20	14,3 x 3	8,8	80	2,47	320	341,29 €
UTK3-SWRR	30,0	8,0	58	1000	20	14,3 x 5	8,8	80	5,36	910	505,79 €

Dimensions in mm

 
Fax: 0 825 88 6000 Service 0,15€/mln + prix appel

cial2@hpceurope.com

WEB  
04/2020

HPC

## Our other products



CXS

External circlip  
DIN471, external DIN  
471



HLA24

Right angle spiro  
bevel gearbox, Up to  
78Nm



SMS

Spiral bevel gear, 1:1



BABV

Ball lock pins lockable  
, Stainless steel



KKSS

Rounded end feather  
key, Stainless steel



LWL

Linear ball slide -  
Stainless steel balls,  
Chariot - from 514 N  
to 1...



LRR

Catch-plate for latch,  
Catch-plate



GE\_ET\_2RS

Spherical bushing,  
Hard chromium /  
Teflon contact with  
seals



MO

Worm and wheel set,  
Hardened steel



CHT

Asynchronous AC  
motor 0.12 to 0.22kW,  
0.12 to 0.22kW



PF60

Worm and wheel gear  
reducer, up to 118  
Nm



GCH

Linear ball slide Eco  
Range, economy  
range

## Complementary products



UTKswcr

Utilitak® 3 wheels  
carriage, Steel roller  
carriage



UTKswr

Utilitak® V rail, V rail



UTKswcr

Utilitak® 3 wheels  
carriage, Steel roller  
carriage