



V shaped channel UtiliTrak®

Steel


HEPCO

UTKSWRR

- For use with STK-PWCR roller carriages
- Carbon bearing steel with hardened steel raceways
- Smoothness Ra 0.8µm
- Length may vary +/- 2mm

Option

- Max rail length : 3600mm

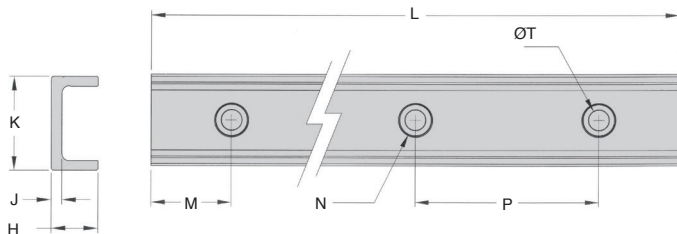

DISCOUNTS

Qty	1+	2+	4+
Disc. List	-10%	On request	

Part number	H	J	K	L	M	Dia x depth (counterbore) (Ø hole)	T	P	Rail weight (kg/m)	Slide weight (g)	Price each
UTK1-SWRR	15,0	4,0	26	1000	20	9,8 x 2,8	5,8	80	1,33	121	266,56 €
UTK2-SWRR	19,7	4,5	40	1000	20	14,3 x 3	8,8	80	2,47	320	341,29 €
UTK3-SWRR	30,0	8,0	58	1000	20	14,3 x 5	8,8	80	5,36	910	505,79 €

Dimensions in mm

Fax: 0 825 88 6000 Service 0,15€/mln + prix appel

cial2@hpceurope.com

WEB
04/2020

HPC

Our other products



DB
Steel bevel gear, 2:1



PSG3
Spur gear - precision range, Pre-hardened Steel 35NCD6



NSB
Standard linear bearing housing, Closed - Long



BABreceptacle
Ball pin socket, Socket



AC
Strike for toggle latch, 15mm



FDS
Flexible drive shaft, Masterflex® Steel, with PVC casing



OP3_14_06
Reducing sleeve for OP indicators, Reduction socket



BAC105
Storage bin, 8mm



SDA
Locking bolt support bracket, Mounting holes parallel to locating bolt



PPRss
Pad eye on mounting plate round, Stainless steel



HCA
Magnetic screw with socket, Steel



MSP3815
Masterplate® glueable insert rectangular, rectangular with tapped i...

Complementary products



UTKswcr
Utilitrak® 3 wheels carriage, Steel roller carriage



UTKswr
Utilitak® V rail, V rail



UTKswcr
Utilitrak® 3 wheels carriage, Steel roller carriage