



3 spoked handwheel without handle

Polyamide

V3RA

- Manual operating element
- Materials:
Wheel: glass fibre reinforced polyamide
Hub: galvanised steel

Options

- Different bore diameters
- Keyways
- See modification info on page 64


Application

- All types of machines



New Ø300
Ø375

Bore modifications

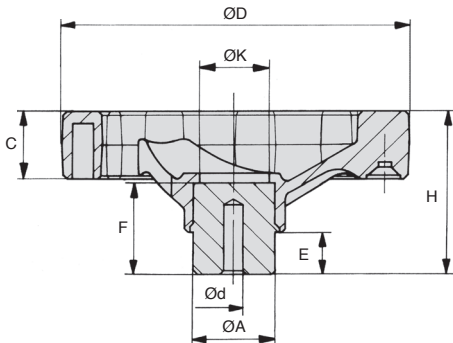

DISCOUNTS

Qty	1+	6+	20+
Disc.	List	-5%	On request

Part number	Ød Pré-bore	ØD	H	C	ØA	E	F	ØK	Stock*	Price each 1 to 5
V3RA-100	4	100	46	20	24	12	24	18	✓	11,42 €
V3RA-125	6	125	51	24	24	12	28	20	✓	14,40 €
V3RA-160	6	160	61	28	32	15	31	30	✓	20,35 €
V3RA-200	6	200	74	32	40	15	40	35	✓	30,68 €
V3RA-250	6	250	83	34	48	17	49	35	-	46,83 €
V3RA-300	6	300	93	36	58	18	53	48	New-	76,20 €
V3RA-375	6	375	104	38	58	18	53	48	New-	113,05 €

*Subject to availability - Dimensions in mm

Our other products



BPV Mss

Stainless steel miniature ball transfer unit, Miniature to screw



CHML63

Worm and wheel gear reducer, up to 138 Nm - Integrated torque limiter



PRF ROUL

Castor for aluminium profile, No brake



ZBconique

Machined plastic bevel gear, 1:1



ACLALF

Adjustable foot for aluminium profile, Ideal for workstations



NCT

Square tube connector, Fixed angle



SH0

Parallel axis helical gear, Machined plastic (delrin)



MSP19

Masterplate® glueable insert Ø19, Cylindrical with tapped insert



PR821

Idle sprocket for slat top chain, Ranges 821



RLXAC8

Free roller, Steel



PTA100

Articulated levelling foot, pressed base



RAS

90° ball and socket joints DIN71802, Steel

Complementary products



HLUss

Spoked handwheel, Stainless steel 316