



3 spoked handwheel with folding handle

Polyamide

V3RAPTR

- **Manual operating element**
- Freely revolving handle for manual operation
- **Materials:**
Wheel: glass fibre reinforced polyamide
Hub: galvanised steel

Info.

- Revolving handle folds away for safety


Options

- Different bore diameters
- Keyways
- See modification info


Application

- All types of machines

Bore modifications

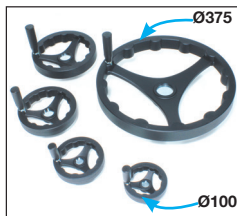

New Ø300
Ø375

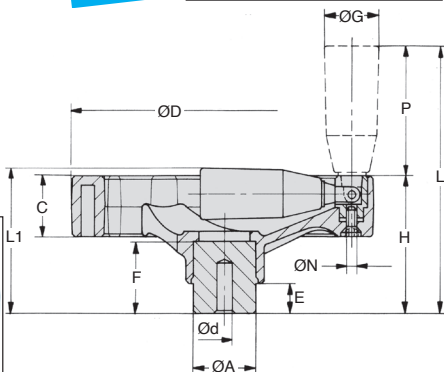

DISCOUNTS

Qty	1+	6+	20+
Disc.	List	-5%	On request

Part number	Ød Pré-bore	ØD	H	C	ØA	E	F	L	L1	ØG	P	ØN	Stock*	Price each 1 to 5
V3RA-100-PTR	4	100	46	20	24	12	24	100	50	21	52	M4	✓	44,81 €
V3RA-125-PTR	6	125	51	24	24	12	28	105	54	21	52	M4	✓	49,50 €
V3RA-160-PTR	6	160	61	28	32	15	31	135	65	23	74	M5	✓	56,22 €
V3RA-200-PTR	6	200	74	32	40	15	40	168	79	26	94	M6	✓	67,27 €
V3RA-250-PTR	6	250	83	34	48	17	49	173	89	26	94	M6	-	81,01 €
V3RA-300-PTR	6	300	93	36	58	18	53	184	100	26	94	M6	New	114,70 €
V3RA-375-PTR	6	375	104	38	58	18	53	195	110	26	94	M6	New	145,13 €

*Subject to availability - Dimensions in mm


Our other products



CHAFR-MINI
Miniature friction
hinge, Friction



 CHMR40
Worm and wheel gear
reducer, up to 57 Nm



STL
Guidance brush -
Brush, Brush



CHTRB
Single and dual
output gearboxes, Up
to 16,5 Nm



APB_T
Adjusting rod for
clamp - Female, Bored



MET
Cylindrical sintered
bronze bush, Self-
lubricating sintered
bronze



DIV_SS
Stainless steel locking
bolt, With grip -
Stainless steel



PPD
Indexing plunger for
sheets, For sheet
metal



SC2
2 part rigid shaft
clamp, Clamping jaw



RURt
Swivel castor with
central hole,
Polyurethane -



ACLEFS
Floor anchor for
aluminium profile,
Adjustable



NT62
Spur gear coaxial
gearbox, from 6 to 18
Nm - Inline

Complementary products



V3RA_PT
3-spoked handwheel
with handle,
Polyamide



PGR
Folding revolving
handle for handwheel,
Folding



SHA_PTR
Handwheel with
folding handle,
Polyamide



MHPGR
Arm with folding
rotating handle,