



# Magnetic stud with central hole

AlNiCo

VAP



- AlNiCo magnets with central through drilled mounting hole
- Both faces are machine finished and have a strong attraction force in a reduced size
- Working temperature -50°C to +450°C
- Good shock resistance

**For recessed mounting, following precautions should be observed**

- in a non-ferrous support: none specified
- in a ferrous support: magnet should be isolated from the support by an air gap or non-ferrous material

## Applications

- Suitable for fixing or positioning of components in reduced spaces and possibly subject to high temperatures
- Positioning of inserts in moulding machines...

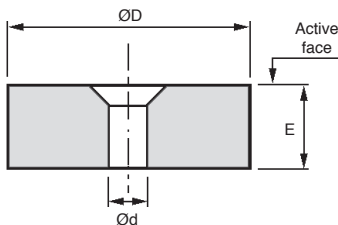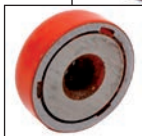

## DISCOUNTS

Qty	1+	6+	20+	40+	60+
Disc.	List	-15%	-20%	-30%	On request

Part number	ØD	Ød	E	F (daN)	Weight (g)	Stock*	Price each 1 to 5
VAP19-8	19	3,5	8,0	3,0	18	✓	6,65 €
VAP28-9	29	5,0	9,0	5,0	46	✓	10,62 €
VAP38-11	38	5,0	10,5	9,5	97	-	15,71 €

\*Depending on availability - Dimensions in mm

## Our other products



PLM-205C

Threaded cylindrical magnet, With threaded hole



VPRA\_M

Handwheel with handle, Thermosetting plastic - stainless steel hub



DOMI120

Connecting kits, XY linking kit



PGM52-M4

Pull handle, Aluminium



PSEC

Security pull handle, Thermoplastic



RDE-N

Sealing washer Hygienic Usit®, Stainless steel - Black EPDM



PVL

Small lobed handle, Polyamide



PM4

Worm and wheel set, Hardened steel



CHINV

Invisible hinge, Invisible - 90° opening



BLH60

Right angled gearbox, from 19 to 70 Nm



RJA00\_02

Sealing strip, Clipping



E15

Right angle helical reducers, from 0.40 to 2.53 Nm

## Complementary products



PLC\_PLT

Magnetic stud with central hole, With central hole



PLC\_PLT

Magnetic stud with threaded hole, With threaded hole