



Magnetic stud with central hole

AlNiCo

VAP



- AlNiCo magnets with central through drilled mounting hole
- Both faces are machine finished and have a strong attraction force in a reduced size
- Working temperature -50°C to +450°C
- Good shock resistance

For recessed mounting, following precautions should be observed

- in a non-ferrous support: none specified
- in a ferrous support: magnet should be isolated from the support by an air gap or non-ferrous material

Applications

- Suitable for fixing or positioning of components in reduced spaces and possibly subject to high temperatures
- Positioning of inserts in moulding machines...

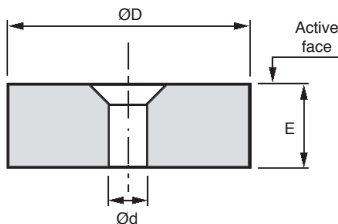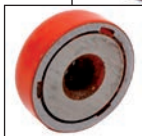

DISCOUNTS

Qty	1+	6+	20+	40+	60+
Disc.	List	-15%	-20%	-30%	On request

Part number	ØD	Ød	E	F (daN)	Weight (g)	Stock*	Price each 1 to 5
VAP19-8	19	3,5	8,0	3,0	18	✓	6,65 €
VAP28-9	29	5,0	9,0	5,0	46	✓	10,62 €
VAP38-11	38	5,0	10,5	9,5	97	-	15,71 €

*Depending on availability - Dimensions in mm

Our other products



SRG

Adjustable latch clamp with catch-plate, Stroke from 78mm to 90mm



VB

Small 6 lobe threaded handle, Duroplast - Stainless steel



G4

Spur gear, Steel 20NCD2



PLM-C

Magnetic stud, Cylindrical holding magnet



CHA_GC_9SS

Stainless steel garnet hinge, To be welded



PAMF100

Articulated fixable foot with pressed base, Ø 100



PCF2

Conical flexible mount, Oval base plate



MHX

Threaded sleeves, Hexagonal - stainless steel



PWDL_PWGDL25

Worm - precision range, Peek



EDS

Support component, 90° angle bracket



PAP

Doorstop and handle, Ergonomic handle



SER

Hinged door accessories, Magnetic doorstop

Complementary products



PLC_PLT

Magnetic stud, With central hole



PLC_PLT

Magnetic stud, With threaded hole