 


- **Dual threaded screw wood/metal**
- Allows a metal object to be fixed to wood
- Materials:
 - Galvanised steel
 - Stainless steel, 304
- Supplied by the pack




Mounting

- Screw should first be inserted into the wood using a suitable spanner
- Compatible with **N, SHN, NINA** and **NIN** nuts



Typical application

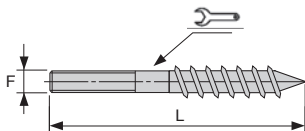

DISCOUNTS Steel

Qty	1+	6+	20+	50+
Disc.	List	-10%	-20%	On request


DISCOUNTS S/steel

Qty	1+	6+	10+
Disc.	List	-5%	On request

Part number	Part number		ØF	L	Qty per pack		Price each 1 to 5	
	Steel	Stainless steel			Steel	S/steel	Steel	S/steel
VCMB5-40/B		-	M5	40	100	-	5,65 €	-
VCMB5-50/B		-	M5	50	100	-	9,36 €	-
VCMB6-60/B	VCMB6-60/SS/B		M6	60	100	100	11,00 €	36,38 €
VCMB6-80/B	VCMB6-80/SS/B		M6	80	100	100	18,18 €	45,69 €
VCMB6-100/B	VCMB6-100/SS/B		M6	100	100	100	29,76 €	61,45 €
VCMB6-120/B	VCMB6-120/SS/B		M6	120	100	100	30,83 €	69,20 €
VCMB8-50/B	VCMB8-50/SS/B		M8	50	100	100	11,75 €	96,98 €
VCMB8-60/B	VCMB8-60/SS/B		M8	60	100	100	12,67 €	57,14 €
VCMB8-80/B	VCMB8-80/SS/B		M8	80	100	50	16,68 €	38,27 €
VCMB8-100/B	VCMB8-100/SS/B		M8	100	100	50	20,78 €	51,87 €
VCMB8-120/B	VCMB8-120/SS/B		M8	120	100	50	25,32 €	60,40 €
VCMB8-140/B	VCMB8-140/SS/B		M8	140	100	50	32,73 €	70,23 €
VCMB8-160/B	VCMB8-160/SS/B		M8	160	100	50	36,56 €	69,36 €
VCMB10-60/B		-	M10	60	100	-	22,32 €	-
VCMB10-80/B	VCMB10-80/SS/B		M10	80	50	25	15,42 €	46,74 €
VCMB10-100/B	VCMB10-100/SS/B		M10	100	50	25	18,88 €	39,09 €
VCMB10-120/B	VCMB10-120/SS/B		M10	120	50	25	33,04 €	46,29 €
VCMB10-140/B	VCMB10-140/SS/B		M10	140	50	25	42,18 €	50,57 €

Dimensions in mm

 Our other products



CAB

Stainless steel cable,
Stainless steel



T5P_T10P

Connecting plate for T
type timing belts, T5



NK17

Drylin®N miniature
guiding system, Width
17 mm



HW_HT

Half-rail guide, Rail



 
SF_ZZ

Deep groove ball
bearing, Stainless
steel



CPAS

Stay with safety
catch, Opens upward



PO

Pull handle - Multi-
sector, Smooth hole



 
DB

Steel bevel gear, 2:1




PO

Pull handle - Multi-
sector, Tapped
recessed insert



SLHHlok

 Horizontal toggle
clamp, Horizontal
toggle clamp /



M1

Worm and wheel set,
Bronze



DBC

Panamech, Multi-
Beam, Aluminium -
with clamping jaw

Complementary products



VCMB

Dual-thread screw
wood/metal, Steel



SHN

Hexagonal nut
DIN934, A2 Stainless
steel



NIN

Self-locking nut, A2
Stainless steel



SHW

Plain washer, A2
Stainless steel