 


- **Dual threaded screw wood/metal**
- Allows a metal object to be fixed to wood
- Materials:
  - Galvanised steel
  - Stainless steel, 304
- Supplied by the pack




### Mounting

- Screw should first be inserted into the wood using a suitable spanner
- Compatible with **N, SHN, NINA** and **NIN** nuts



Typical application

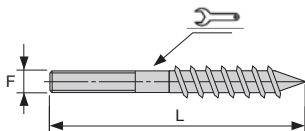

### DISCOUNTS Steel

Qty	1+	6+	20+	50+
Disc.	List	-10%	-20%	On request

### DISCOUNTS S/steel

Qty	1+	6+	10+
Disc.	List	-5%	On request

Part number	Part number		ØF	L	Qty per pack		Price each 1 to 5	
	Steel	Stainless steel			Steel	S/steel	Steel	S/steel
VCMB5-40/B		-	M5	40	100	-	5,65 €	-
VCMB5-50/B		-	M5	50	100	-	9,36 €	-
VCMB6-60/B	VCMB6-60/SS/B		M6	60	100	100	11,00 €	36,38 €
VCMB6-80/B	VCMB6-80/SS/B		M6	80	100	100	18,18 €	45,69 €
VCMB6-100/B	VCMB6-100/SS/B		M6	100	100	100	29,76 €	61,45 €
VCMB6-120/B	VCMB6-120/SS/B		M6	120	100	100	30,83 €	69,20 €
VCMB8-50/B	VCMB8-50/SS/B		M8	50	100	100	11,75 €	96,98 €
VCMB8-60/B	VCMB8-60/SS/B		M8	60	100	100	12,67 €	57,14 €
VCMB8-80/B	VCMB8-80/SS/B		M8	80	100	50	16,68 €	38,27 €
VCMB8-100/B	VCMB8-100/SS/B		M8	100	100	50	20,78 €	51,87 €
VCMB8-120/B	VCMB8-120/SS/B		M8	120	100	50	25,32 €	60,40 €
VCMB8-140/B	VCMB8-140/SS/B		M8	140	100	50	32,73 €	70,23 €
VCMB8-160/B	VCMB8-160/SS/B		M8	160	100	50	36,56 €	69,36 €
VCMB10-60/B		-	M10	60	100	-	22,32 €	-
VCMB10-80/B	VCMB10-80/SS/B		M10	80	50	25	15,42 €	46,74 €
VCMB10-100/B	VCMB10-100/SS/B		M10	100	50	25	18,88 €	39,09 €
VCMB10-120/B	VCMB10-120/SS/B		M10	120	50	25	33,04 €	46,29 €
VCMB10-140/B	VCMB10-140/SS/B		M10	140	50	25	42,18 €	50,57 €

Dimensions in mm

## Our other products



BLH70

Right angled gearbox,  
from 26 to 128 Nm



PRES

Manual workbench  
press accessory for  
PRES-3HR end  
PRES-4HR, Set of s...



 
DB

Steel bevel gear, 2:1



PLC\_PLT

Magnetic stud with  
threaded hole, With  
threaded hole



ZR

Plastic rack, Delrin



ZG0

Plastic spur gear,  
Machined plastic  
(delrin)



LC

Friction clutch, 190 to  
1800 Nm



RGS

Rotex® GS backlash  
free jaw coupling,  
from 0.5 to 190Nm



GMC\_GMK\_BR

Guiding profile clamp,  
Flat or rounded



PTAF100-PAMF100

Articulated fixable  
foot with pressed



YG3

HEAVY DUTY spur  
gear, Steel 35NCD6



PM2

Worm and wheel set,  
Non hardened steel

## Complementary products



VCMB

Dual-thread screw  
wood/metal, Stainless  
steel



SHN

Hexagonal nut  
DIN934, Steel (Class  
6[8])



NIN

Self-locking nut, Steel



SHW

Plain washer, Steel