

# Self-gripping cable strip

## VEL For electric and pneumatic cables

### - Velcro type tie for fixing or bundling cables

- 1 "loop" side, 1 "hook" side
- Ideal for fixing cables on aluminum profiles with the VEL-PRF bases
- Sold in roll
- Materials:  
Self-extinguishing polypropylene according to UL94-V2



### Advantages

- Easy mounting
- Reusable hundreds of times
- Different sizes of hook-and-loop strips available
- No risk of injury or damage to cables unlike Rilsan cable ties
- Cut-out for easy lengthening.

### Accessories

- VEL-M or VEL-PRF base



Use on the base



Use alone

### DISCOUNTS

Qty	1+	2+	4+
Disc.	List	-10%	On request

Part number	Width (mm)	Length (metre)	Price each
VEL7.5-15/B	7,5	15	38,59 €
VEL10-25/B	10	25	80,53 €
VEL20-25/B	20	25	98,98 €
VEL30-25/B	30	25	204,70 €

\*Depending on availability - Dimensions in mm

# Clip-on base for hook-and-loop strip

For electric and pneumatic cables

VELPRF

- Support clip for Velcro type hook-and-loop strip

- Connecting element for fixing a cable on a **Minitec PRF** aluminum profile
- Anti-return clip (the strips can only pass in one direction) for optimum cable tightening
- Materials:

Glass fiber reinforced polyamide  
self-extinguishing according to UL94-V0



## Advantages



- Easy mounting by 45° rotation
- Reusable
- Different sizes of hook-and-loop strips available

## Accessories

- VEL stripe



clip-on  
on PRF profile

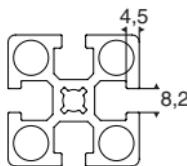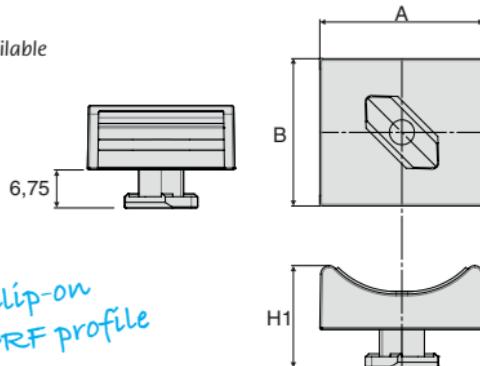

## DISCOUNTS

Qty	1+	10+	20+	50+
Disc.	List	-5%	-10%	On request

Part number	Range of Tightening (mm)	For strip Width (mm)	A	B	H1	Price each 1 to 9
VEL7.5-PRF-420	4-20	7,5/10	19	15	15,35	4,19 €
VEL10-PRF-420	4-20	7,5/10	19	15	15,35	4,19 €
VEL20-PRF-835	8-35	20	29	26	18,05	4,36 €
VEL20-PRF-1060	10-60	20	36	26	18,05	4,51 €

\*Depending on availability - Dimensions in mm

# Screw-on base for hook-and-loop

**VELM** For electric and pneumatic cables

- **Support clip for Velcro type hook-and-loop strip**

- Anti-return clip (the strips can only pass in one direction) for optimum cable tightening

- Materials:

Glass fiber reinforced polyamide  
self-extinguishing according to UL94-V0





For 7.5 to 20 mm  
strips

## Advantages

- Easy mounting by screwing
- Reusable
- Different sizes of hook-and-loop strips available

## Accessories

 - **VEL** stripe
- **PRF-ECL** nut and **FHC** screw

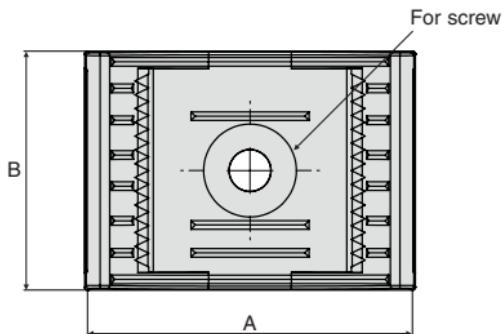

## DISCOUNTS

Qty	1+	10+	20+	50+
Disc.	List	-5%	-10%	On request

Part number	Range of tightening (mm)	For screw	For strips width (mm)	A	B	H	Price each 1 to 9
VEL7.5-M4-420	4-20	M4	7,5	18,6	15	8,6	3,68 €
VEL10-M4-420	4-20	M4	10,0	18,6	15	8,6	3,68 €
VEL20-M5-835	8-35	M4/M5	20,0	29,0	26	11,3	3,85 €
VEL20-M5-1060	10-60	M4/M5	20,0	36,0	26	11,3	4,01 €

\*Depending on availability - Dimensions in mm

# Screw-on base for hook-and-loop

For electric and pneumatic cables

VELM

## - Support clip for Velcro type hook-and-loop strip

- Anti-return clip (the strips can only pass in one direction) for optimum cable tightening

## - Materials:

Glass fiber reinforced polyamide  
self-extinguishing according to UL94-V0




For strip  
30mm

## Advantages

- Easy mounting by screwing
- Reusable

## Accessories

- VEL stripe
- PRF-ECL nut and CHC6 screw

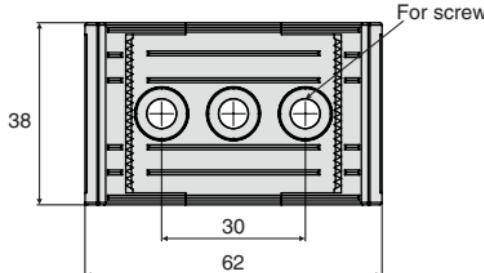

## DISCOUNTS

Qty	1+	10+	20+	50+
Disc.	List	-5%	-10%	On request

Part number	Range of tightening (mm)	For screw	For strips width (mm)	Price each
VEL30-M6-20100	20-100	M6	30	1 to 9 7,70 €

Dimensions in mm

## Our other products



BLHT70  
Right angled gearbox,  
from 26 to 128 Nm



BIMSS  
Indexing plunger mini,  
miniature - Stainless  
steel



BPLF  
Ball transfer unit light  
duty, Light



TCL-ECL  
Support rod for heavy  
loads, Support spindle



SDCss  
Positioning sleeve for  
indexing pin, For pin  
Ø4 to Ø12



GG3  
Ground spur gear,  
Heat treated steel



CLSCLP\_SS  
Clevis components,  
short version,  
Stainless steel - short  
range



APBC  
Circular rod, Round  
rod



BEAS  
Knob star grip  
antistatic, Star, anti-



GPB  
Threaded spherical  
knob, Moulded thread



MCLred  
Reducing sleeve  
female/female,



TPEf  
Castor for aluminium  
profile, Fixed

## Complementary products



VELprf  
Clip-on base for hook-  
and-loop strip,  
Polyamide



VELM4  
Screw-on base for  
hook-and-loop strip,  
Polyamide



VELM6  
Screw-on base for  
hook-and-loop strip,  
Polyamide