

Self-gripping cable strip

VEL For electric and pneumatic cables

- Velcro type tie for fixing or bundling cables
- 1 "loop" side, 1 "hook" side
- Ideal for fixing cables on aluminum profiles with the **VEL-PRF** bases
- Sold in roll
- Materials:
Self-extinguishing polypropylene according to UL94-V2

Advantages

- Easy mounting
- Reusable hundreds of times
- Different sizes of hook-and-loop strips available
- No risk of injury or damage to cables unlike Rilsan cable ties
- Cut-out for easy lengthening.

Accessories

- **VEL-M** or **VEL-PRF** base



Use on the base



Use alone

DISCOUNTS

Qty	1+	2+	4+
Disc.	List	-10%	On request

Part number	Width (mm)	Length (metre)	Price each
VEL7.5-15/B	7,5	15	38,59 €
VEL10-25/B	10	25	80,53 €
VEL20-25/B	20	25	98,98 €
VEL30-25/B	30	25	204,70 €

*Depending on availability - Dimensions in mm

Clip-on base for hook-and-loop strip

For electric and pneumatic cables **VELPRF**




- **Support clip for Velcro type hook-and-loop strip**
- Connecting element for fixing a cable on a **Minitec PRF** aluminum profile
- Anti-return clip (the strips can only pass in one direction) for optimum cable tightening
- Materials:
Glass fiber reinforced polyamide
self-extinguishing according to UL94-V0

Advantages

- Easy mounting by 45° rotation
- Reusable
- Different sizes of hook-and-loop strips available

Accessories

- **VEL** stripe

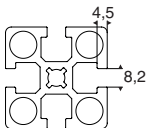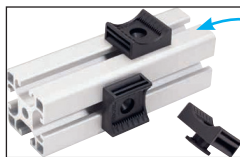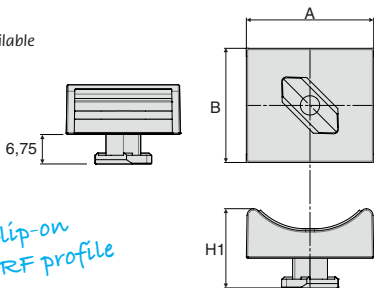

DISCOUNTS

Qty	1+	10+	20+	50+
Disc.	List	-5%	-10%	On request

Part number	Range of Tightening (mm)	For strip Width (mm)	A	B	H1	Price each 1 to 9
VEL7.5-PRF-420	4-20	7,5/10	19	15	15,35	4,19 €
VEL10-PRF-420	4-20	7,5/10	19	15	15,35	4,19 €
VEL20-PRF-835	8-35	20	29	26	18,05	4,36 €
VEL20-PRF-1060	10-60	20	36	26	18,05	4,51 €

*Depending on availability - Dimensions in mm

Screw-on base for hook-and-loop

VELM For electric and pneumatic cables

- **Support clip for Velcro type hook-and-loop strip**
- Anti-return clip (the strips can only pass in one direction) for optimum cable tightening
- Materials:
Glass fiber reinforced polyamide
self-extinguishing according to UL94-V0

Advantages



- Easy mounting by screwing
- Reusable
- Different sizes of hook-and-loop strips available

Accessories

- VEL stripe
- PRF-ECL nut and FHC screw



 For 7.5 to 20 mm
strips

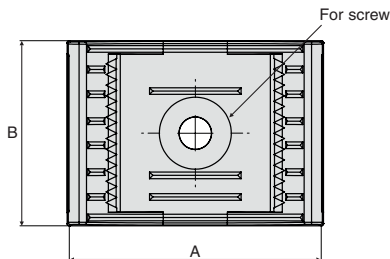

DISCOUNTS

Qty	1+	10+	20+	50+
Disc.	List	-5%	-10%	On request

Part number	Range of tightening (mm)	For screw	For strips width (mm)	A	B	H	Price each
VEL7.5-M4-420	4-20	M4	7,5	18,6	15	8,6	1 to 9 3,68 €
VEL10-M4-420	4-20	M4	10,0	18,6	15	8,6	3,68 €
VEL20-M5-835	8-35	M4/M5	20,0	29,0	26	11,3	3,85 €
VEL20-M5-1060	10-60	M4/M5	20,0	36,0	26	11,3	4,01 €

*Depending on availability - Dimensions in mm

Screw-on base for hook-and-loop

For electric and pneumatic cables

VELM

- Support clip for Velcro type hook-and-loop strip
- Anti-return clip (the strips can only pass in one direction) for optimum cable tightening
- Materials:
Glass fiber reinforced polyamide
self-extinguishing according to UL94-V0

Advantages


 
- Easy mounting by screwing
- Reusable

Accessories

- VEL stripe
- PRF-ECL nut and CHC6 screw



For strip
30mm

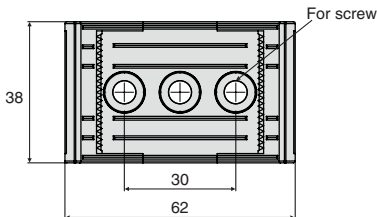

DISCOUNTS

Qty	1+	10+	20+	50+
Disc.	List	-5%	-10%	On request

Part number	Range of tightening (mm)	For screw	For strips width (mm)	Price each 1 to 9
VEL30-M6-20100	20-100	M6	30	7,70 €

Dimensions in mm


Our other products



PSG15
Spur gear - precision range, Pre-hardened Steel 35NCD6



CLM
Male clevis end, Steel short

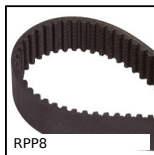

RPP8
RPP heavy duty timing belt, RPP8



GG2
Ground spur gear, Heat treated steel



BLHB40
Right angled gearbox, bored shafts, up to 10.3 Nm



PSPE22
Conical flexible shaft handle Ø22, Black PVC




CHA35
Hinge for aluminium profile, Hinge



PDR-RD
Mounting feet with integrated castors, Offset castor



 PPF
Indexing plunger with flange, with drilled



MR_MMR
Metric section rack, Steel



T5M_T10M
T type timing belt per metre, T10 Steel



BL15
Right angled gearbox, from 1.10 to 6 Nm

Complementary products



VEL
Self-gripping cable strip, electric and pneumatic cables



VELprf
Clip-on base for hook-and-loop strip, Polyamide



VELM6
Screw-on base for hook-and-loop strip, Polyamide