

Self-gripping cable strip

VEL For electric and pneumatic cables

- Velcro type tie for fixing or bundling cables
- 1 "loop" side, 1 "hook" side
- Ideal for fixing cables on aluminum profiles with the VEL-PRF bases
- Sold in roll
- Materials:
Self-extinguishing polypropylene according to UL94-V2

Advantages

- Easy mounting
- Reusable hundreds of times
- Different sizes of hook-and-loop strips available
- No risk of injury or damage to cables unlike Rilsan cable ties
- Cut-out for easy lengthening.

Accessories

- VEL-M or VEL-PRF base



Use on the base



Use alone

DISCOUNTS

Qty	1+	2+	4+
Disc.	List	-10%	On request

Part number	Width (mm)	Length (metre)	Price each
VEL7.5-15/B	7,5	15	38,59 €
VEL10-25/B	10	25	80,53 €
VEL20-25/B	20	25	98,98 €
VEL30-25/B	30	25	204,70 €

*Depending on availability - Dimensions in mm

Clip-on base for hook-and-loop strip

For electric and pneumatic cables **VELPRF**

- Support clip for Velcro type hook-and-loop strip
- Connecting element for fixing a cable on a **Minitec PRF** aluminum profile
- Anti-return clip (the strips can only pass in one direction) for optimum cable tightening
- Materials:
Glass fiber reinforced polyamide
self-extinguishing according to UL94-V0






Advantages

- Easy mounting by 45° rotation
- Reusable
- Different sizes of hook-and-loop strips available

Accessories

- VEL stripe

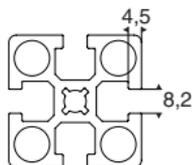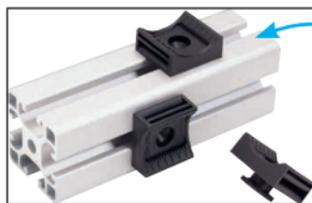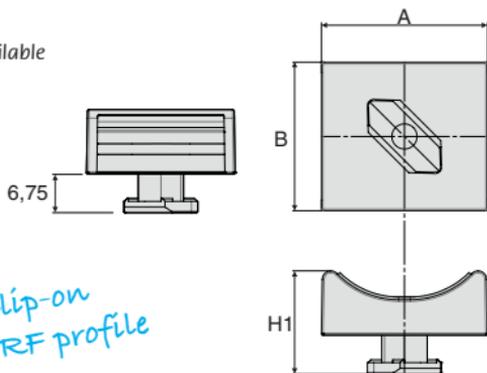

DISCOUNTS

Qty	1+	10+	20+	50+
Disc. List		-5%	-10%	On request

Part number	Range of Tightening (mm)	For strip Width (mm)	A	B	H1	Price each
						1 to 9
VEL7.5-PRF-420	4-20	7,5/10	19	15	15,35	4,19 €
VEL10-PRF-420	4-20	7,5/10	19	15	15,35	4,19 €
VEL20-PRF-835	8-35	20	29	26	18,05	4,36 €
VEL20-PRF-1060	10-60	20	36	26	18,05	4,51 €

*Depending on availability - Dimensions in mm

Screw-on base for hook-and-loop

VELM For electric and pneumatic cables

- Support clip for Velcro type hook-and-loop strip
- Anti-return clip (the strips can only pass in one direction) for optimum cable tightening
- Materials:
Glass fiber reinforced polyamide
self-extinguishing according to UL94-V0

Advantages



- Easy mounting by screwing
- Reusable
- Different sizes of hook-and-loop strips available

Accessories

- VEL stripe
- PRF-ECL nut and FHC screw



 For 7.5 to 20 mm strips

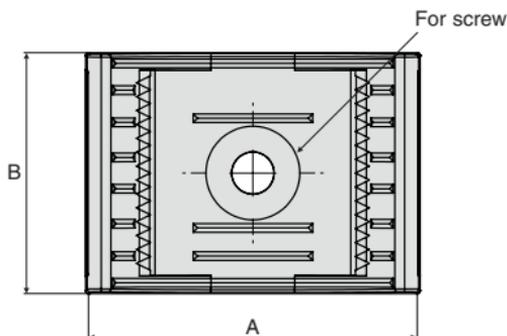

DISCOUNTS

Qty	1+	10+	20+	50+
Disc.	List	-5%	-10%	On request

Part number	Range of tightening (mm)	For screw	For strips width (mm)	A	B	H	Price each
							1 to 9
VEL7.5-M4-420	4-20	M4	7,5	18,6	15	8,6	3,68 €
VEL10-M4-420	4-20	M4	10,0	18,6	15	8,6	3,68 €
VEL20-M5-835	8-35	M4/M5	20,0	29,0	26	11,3	3,85 €
VEL20-M5-1060	10-60	M4/M5	20,0	36,0	26	11,3	4,01 €

*Depending on availability - Dimensions in mm

Screw-on base for hook-and-loop

For electric and pneumatic cables

VELM

- Support clip for Velcro type hook-and-loop strip
- Anti-return clip (the strips can only pass in one direction) for optimum cable tightening
- Materials:
Glass fiber reinforced polyamide
self-extinguishing according to UL94-V0

Advantages


- Easy mounting by screwing
- Reusable

Accessories

- VEL stripe
- PRF-ECL nut and CHC6 screw



For strip
30mm

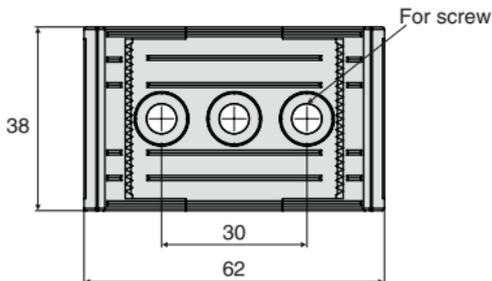

DISCOUNTS

Qty	1+	10+	20+	50+
Disc. List		-5%	-10%	On request

Part number	Range of tightening (mm)	For screw	For strips width (mm)	Price each 1 to 9
VEL30-M6-20100	20-100	M6	30	7,70 €

Dimensions in mm

Our other products




PC562K
Chain sprocket with
hardened teeth,
15.875mm (DIN10B-1)



PGM86-M5
Push/Pull handle,
Thermoplastic



GG1
Ground spur gear,
Heat treated steel

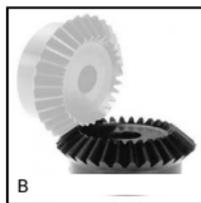

B
Steel bevel gear, 1:1



RJA00_28
Sealing strip, Clipping



SVG
Adjustable latch
clamp with strike
plate, Stroke from
118mm to 130,5mm



BLHB30
Right angled gearbox,
bored shafts, up to
4.4 Nm



CFF
Female rod ends DIN
ISO12240-4, Steel /
bronze



CHAPAMss
Weld-on hinge with
flat end, Stainless



PARF110
Pressed steel base
rigid foot, Swivelling



VCMB
Dual-thread screw
wood/metal, Stainless



BMM
Knurled knob - male,
Knurled

Complementary products



VEL
Self-gripping cable
strip, electric and
pneumatic cables



VELprf
Clip-on base for hook-
and-loop strip,
Polyamide



VELM6
Screw-on base for
hook-and-loop strip,
Polyamide