

Self-gripping cable strip

VEL For electric and pneumatic cables

- Velcro type tie for fixing or bundling cables

- 1 "loop" side, 1 "hook" side
- Ideal for fixing cables on aluminum profiles with the VEL-PRF bases
- Sold in roll
- Materials:
Self-extinguishing polypropylene according to UL94-V2



Advantages

- Easy mounting
- Reusable hundreds of times
- Different sizes of hook-and-loop strips available
- No risk of injury or damage to cables unlike Rilsan cable ties
- Cut-out for easy lengthening.

Accessories

- VEL-M or VEL-PRF base



Use on the base



Use alone

DISCOUNTS

Qty	1+	2+	4+
Disc.	List	-10%	On request

Part number	Width (mm)	Length (metre)	Price each
VEL7.5-15/B	7,5	15	38,59 €
VEL10-25/B	10	25	80,53 €
VEL20-25/B	20	25	98,98 €
VEL30-25/B	30	25	204,70 €

*Depending on availability - Dimensions in mm

Clip-on base for hook-and-loop strip

For electric and pneumatic cables

VELPRF

- Support clip for Velcro type hook-and-loop strip

- Connecting element for fixing a cable on a **Minitec PRF** aluminum profile
- Anti-return clip (the strips can only pass in one direction) for optimum cable tightening
- Materials:

Glass fiber reinforced polyamide
self-extinguishing according to UL94-V0



Advantages



- Easy mounting by 45° rotation
- Reusable
- Different sizes of hook-and-loop strips available

Accessories

- VEL stripe



clip-on
on PRF profile

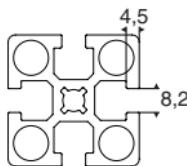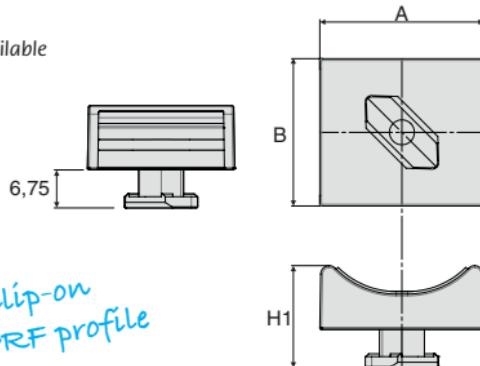

DISCOUNTS

Qty	1+	10+	20+	50+
Disc.	List	-5%	-10%	On request

Part number	Range of Tightening (mm)	For strip Width (mm)	A	B	H1	Price each 1 to 9
VEL7.5-PRF-420	4-20	7,5/10	19	15	15,35	4,19 €
VEL10-PRF-420	4-20	7,5/10	19	15	15,35	4,19 €
VEL20-PRF-835	8-35	20	29	26	18,05	4,36 €
VEL20-PRF-1060	10-60	20	36	26	18,05	4,51 €

*Depending on availability - Dimensions in mm

Screw-on base for hook-and-loop

VELM For electric and pneumatic cables

- Support clip for Velcro type hook-and-loop strip

- Anti-return clip (the strips can only pass in one direction) for optimum cable tightening
- Materials:
Glass fiber reinforced polyamide
self-extinguishing according to UL94-V0




 
For 7,5 to 20 mm
strips

Advantages

- Easy mounting by screwing
- Reusable
- Different sizes of hook-and-loop strips available

Accessories

- VEL stripe
- PRF-ECL nut and FHC screw

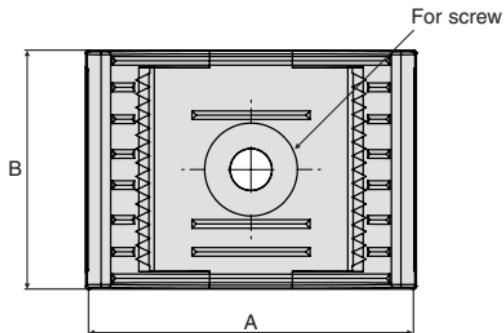

DISCOUNTS

Qty	1+	10+	20+	50+
Disc.	List	-5%	-10%	On request

Part number	Range of tightening (mm)	For screw	For strips width (mm)	A	B	H	Price each 1 to 9
VEL7,5-M4-420	4-20	M4	7,5	18,6	15	8,6	3,68 €
VEL10-M4-420	4-20	M4	10,0	18,6	15	8,6	3,68 €
VEL20-M5-835	8-35	M4/M5	20,0	29,0	26	11,3	3,85 €
VEL20-M5-1060	10-60	M4/M5	20,0	36,0	26	11,3	4,01 €

*Depending on availability - Dimensions in mm

Screw-on base for hook-and-loop

For electric and pneumatic cables

VELM

- Support clip for Velcro type hook-and-loop strip

- Anti-return clip (the strips can only pass in one direction) for optimum cable tightening

- Materials:

Glass fiber reinforced polyamide
self-extinguishing according to UL94-V0




For strip
30mm

Advantages

- Easy mounting by screwing
- Reusable

Accessories

- VEL stripe
- PRF-ECL nut and CHC6 screw

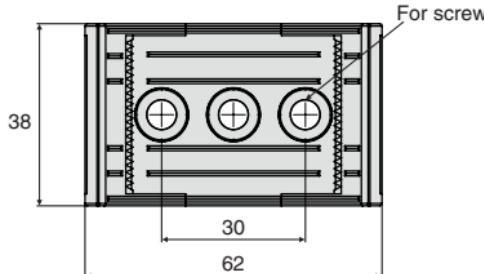

DISCOUNTS

Qty	1+	10+	20+	50+
Disc.	List	-5%	-10%	On request

Part number	Range of tightening (mm)	For screw	For strips width (mm)	Price each
VEL30-M6-20100	20-100	M6	30	7,70 €

Dimensions in mm

Our other products



GAL21
Conveyor wheel,
Plastic



CHA1056-UPA
Molded polyamide
face-mounted hinge,
Black polyamide



PRF1932
Standard aluminium
profile, 19 x 32 mm



QNUP
Single row cylindrical
roller bearing, 1 fixed
inner flange and 1 fr...



BPHF
Ball transfer unit push
fit, Heavy



GLB
Small 6 lobe threaded
handle - female,
Technopolymer -
Stainless steel



CHT
Asynchronous AC
motor 0.12 to 0.22kW,
0.12 to 0.22kW



ACAss
Stainless steel splined
shaft, Stainless steel



NKIB
Combined bearing
with inner ring, Axial
load in both directions



AT5-10ECO
AT type timing pulley,
Economy range - AT5
aluminium



CHM110
Worm and wheel gear
reducer, up to 980
Nm



CTss
Universal joint,
telescopic, Inox, Light
duty

Complementary products



VEL
Self-gripping cable
strip, electric and
pneumatic cables



VELprf
Clip-on base for hook-
and-loop strip,
Polyamide



VELM6
Screw-on base for
hook-and-loop strip,
Polyamide