


Embase à clipser pour bande auto-agrippante

Pour câbles électriques et pneumatiques VELPRF

- Clip support pour bande auto-agrippante type Velcro
- Élément de liaison permettant de fixer un câble sur un profilé aluminium Minitec PRF
- Clip anti-retour (les bandes ne peuvent passer que dans un sens) permettant un serrage des câbles optimum
- Matières :
Polyamide renforcé fibres de verre auto-extinguible selon UL94-V0

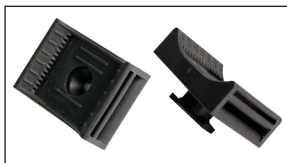


Avantages



- Montage facile par rotation à 45°
- Réutilisable
- Différentes tailles de bandes auto-agrippantes possibles

Accessoires

- Bande VEL

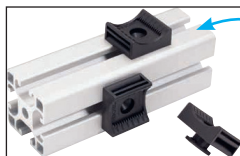

A clipser sur profilé PRF

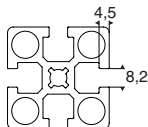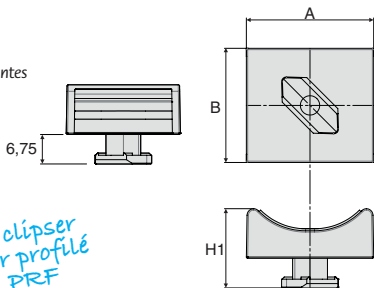

REMISES

Qté	1+	10+	20+	50+
Rem. Prix	-5%	-10%	Sur demande	

Références	Plage de Serrage (mm)	Pour bande Largeur (mm)	A	B	H1	Prix Uni. 1 à 9
VEL7.5-PRF-420	4-20	7,5/10	19	15	15,35	4,15 €
VEL10-PRF-420	4-20	7,5/10	19	15	15,35	4,15 €
VEL20-PRF-835	8-35	20	29	26	18,05	4,32 €
VEL20-PRF-1060	10-60	20	36	26	18,05	4,47 €

*Dans la limite du disponible - Dimensions en mm

Our other products




PRF_PL_4590

Joining plate for aluminium profile, Joint plate - 45x90 mm



DOMI80

 Accessories, Plate



VKM

Square steel nut, Steel - 1 thread



BPM_LOK

Long-Lok slotted spring plunger with ball tip, LONG-LOK - Steel



TSM_T10M

T type timing belt per metre, T5 Steel cored polyurethane



RURt

Swivel castor with central hole, Polyurethane - Aluminium rim (Free



BPLE

Ball transfer unit push fit, Light



RT61ss

Self-centering locking Assembly, Medium/low torque



CMM

Male rod ends DIN ISO12240-4, Steel / bronze



ZHBRA

Plastic bevel gear, 1,25:1 2:1 3:1



RTK

BoWex® curved tooth gear coupling, Nylon and steel



ZG0

Plastic spur gear, Machined plastic (delrin)

Complementary products



VEL

Self-gripping cable strip, electric and pneumatic cables



VELM4

Screw-on base for hook-and-loop strip, Polyamide



VELM6

Screw-on base for hook-and-loop strip, Polyamide