


Embase à clipser pour bande auto-agrippante

Pour câbles électriques et pneumatiques VELPRF

- Clip support pour bande auto-agrippante type Velcro
- Élément de liaison permettant de fixer un câble sur un profilé aluminium Minitec PRF
- Clip anti-retour (les bandes ne peuvent passer que dans un sens) permettant un serrage des câbles optimum
- Matières :
Polyamide renforcé fibres de verre auto-extinguible selon UL94-V0

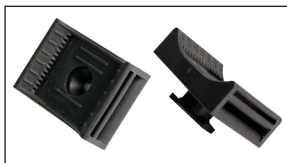


Avantages



- Montage facile par rotation à 45°
- Réutilisable
- Différentes tailles de bandes auto-agrippantes possibles

Accessoires

- Bande VEL

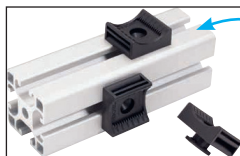

A clipser sur profilé PRF

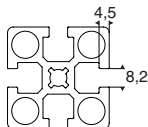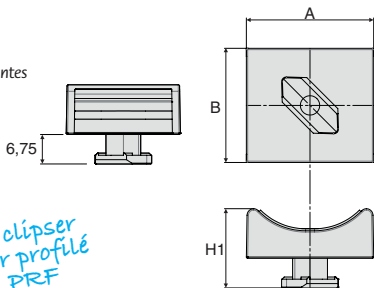

REMISES

Qté	1+	10+	20+	50+
Rem. Prix	-5%	-10%	Sur demande	

Références	Plage de Serrage (mm)	Pour bande Largeur (mm)	A	B	H1	Prix Uni. 1 à 9
VEL7.5-PRF-420	4-20	7,5/10	19	15	15,35	4,15 €
VEL10-PRF-420	4-20	7,5/10	19	15	15,35	4,15 €
VEL20-PRF-835	8-35	20	29	26	18,05	4,32 €
VEL20-PRF-1060	10-60	20	36	26	18,05	4,47 €

*Dans la limite du disponible - Dimensions en mm

Our other products



ACLERP

Roller block for aluminium profile, With guide rail



PSG1255

Spur gear - precision range, Stainless steel 303



DB

Steel bevel gear, 2:1



MHW

Double-disc flexible coupling, Double disk



PRF-SRA-78

Lock for aluminium profile, Quick fitting, self locking door lock



VTLF

3 lobed handle, Polyamide - Brass



CLASS

Stainless steel indexing handle - male, Stainless steel



BOX-TOR-H

Box set of Nitrile O-rings in nitrile, 3.00 x 2.00mm to 45.20 x 4.00



CAP820

Slim slat top chain acetal, Narrow straight range 820



ADL_M

Male eye bolt conforms to DIN580, Steel



ACLBTS

Spherical ended stop for aluminium profile, Spherical ended stop



PRF_RR

Coupling bar for aluminium profile, Coupling bar

Complementary products



VEL

Self-gripping cable strip, electric and pneumatic cables



VELM4

Screw-on base for hook-and-loop strip, Polyamide



VELM6

Screw-on base for hook-and-loop strip, Polyamide