

# Hexagonal headed bolt with narrow shaft

## VHTMHDSS

## Hygienic Design®

- **Thin shaft bolts for use in hygienic environments**

- **Material:**

Stainless steel 1.4404 (316L)


Polished finish Ra<0.8

### Advantages

- In combination with a clamping element, these thin shafted screws are designed against becoming detached accidentally, thus meeting the requirements of European standard 2006/42/EG
- Dirt and residues of product or cleaning materials will not remain, ensuring easy cleaning

### Accessories

- **RDS** safety washer to secure the screw to the other component before assembly (see page 60)

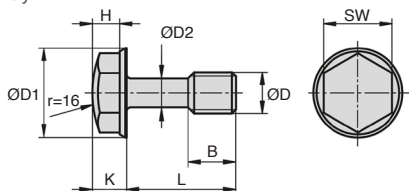

### DISCOUNTS

Qty	1+	5+	10+	25+	50+
Disc.	Net	-5%	-10%	-15%	On request

Part N°	ØD	ØD1	ØD2	H	B	K	L	SW	Price each
									1 to 4
VHTM4-8/HDSS	M4	9,2	3,1	3,0	5,0	4,0	8,0	7,0	6,25 €
VHTM4-10/HDSS	M4	9,2	3,1	3,0	5,0	4,0	10,0	7,0	6,28 €
VHTM4-12/HDSS	M4	9,2	3,1	3,0	5,0	4,0	12,0	7,0	6,37 €
VHTM4-16/HDSS	M4	9,2	3,1	3,0	5,0	4,0	16,0	7,0	6,43 €
VHTM4-20/HDSS	M4	9,2	3,1	3,0	5,0	4,0	20,0	7,0	6,49 €
VHTM5-8/HDSS	M5	10,5	3,7	3,7	6,0	4,7	8,0	8,0	6,49 €
VHTM5-10/HDSS	M5	10,5	3,7	3,7	6,0	4,7	10,0	8,0	6,58 €
VHTM5-12/HDSS	M5	10,5	3,7	3,7	6,0	4,7	12,0	8,0	6,64 €
VHTM5-16/HDSS	M5	10,5	3,7	3,7	6,0	4,7	16,0	8,0	6,72 €
VHTM5-20/HDSS	M5	10,5	3,7	3,7	6,0	4,7	20,0	8,0	6,78 €
VHTM5-25/HDSS	M5	10,5	3,7	3,7	6,0	4,7	25,0	8,0	6,90 €

All dimensions in mm

Part N°	ØD	ØD1	ØD2	H	B	K	L	SW	Price each 1 to 4
VHTM6-8/HDSS	M6	13,0	4,2	4,0	7,0	5,0	8,0	10,0	7,05 €
VHTM6-12/HDSS	M6	13,0	4,2	4,0	7,0	5,0	12,0	10,0	7,18 €
VHTM6-16/HDSS	M6	13,0	4,2	4,0	7,0	5,0	16,0	10,0	7,35 €
VHTM6-20/HDSS	M6	13,0	4,2	4,0	7,0	5,0	20,0	10,0	7,47 €
VHTM6-25/HDSS	M6	13,0	4,2	4,0	7,0	5,0	25,0	10,0	7,66 €
VHTM6-30/HDSS	M6	13,0	4,2	4,0	7,0	5,0	30,0	10,0	7,82 €
VHTM6-35/HDSS	M6	13,0	4,2	4,0	7,0	5,0	35,0	10,0	7,97 €
VHTM6-40/HDSS	M6	13,0	4,2	4,0	7,0	5,0	40,0	10,0	8,19 €
VHTM6-45/HDSS	M6	13,0	4,2	4,0	7,0	5,0	45,0	10,0	8,35 €
VHTM6-50/HDSS	M6	13,0	4,2	4,0	7,0	5,0	50,0	10,0	8,48 €
VHTM6-60/HDSS	M6	13,0	4,2	4,0	7,0	5,0	60,0	10,0	8,89 €
VHTM8-16/HDSS	M8	16,8	6,0	5,5	9,0	6,5	16,0	13,0	8,09 €
VHTM8-20/HDSS	M8	16,8	6,0	5,5	9,0	6,5	20,0	13,0	8,35 €
VHTM8-25/HDSS	M8	16,8	6,0	5,5	9,0	6,5	25,0	13,0	8,57 €
VHTM8-30/HDSS	M8	16,8	6,0	5,5	9,0	6,5	30,0	13,0	8,86 €
VHTM8-35/HDSS	M8	16,8	6,0	5,5	9,0	6,5	35,0	13,0	9,11 €
VHTM8-40/HDSS	M8	16,8	6,0	5,5	9,0	6,5	40,0	13,0	9,33 €
VHTM8-45/HDSS	M8	16,8	6,0	5,5	9,0	6,5	45,0	13,0	9,62 €
VHTM8-50/HDSS	M8	16,8	6,0	5,5	9,0	6,5	50,0	13,0	9,87 €
VHTM8-60/HDSS	M8	16,8	6,0	5,5	9,0	6,5	60,0	13,0	10,40 €
VHTM8-65/HDSS	M8	16,8	6,0	5,5	9,0	6,5	65,0	13,0	10,69 €
VHTM8-70/HDSS	M8	16,8	6,0	5,5	9,0	6,5	70,0	13,0	10,97 €
VHTM10-20/HDSS	M10	20,6	7,7	7,3	12,0	8,3	20,0	16,0	9,62 €
VHTM10-25/HDSS	M10	20,6	7,7	7,3	12,0	8,3	25,0	16,0	9,99 €
VHTM10-30/HDSS	M10	20,6	7,7	7,3	12,0	8,3	30,0	16,0	10,37 €
VHTM10-35/HDSS	M10	20,6	7,7	7,3	12,0	8,3	35,0	16,0	10,75 €
VHTM10-40/HDSS	M10	20,6	7,7	7,3	12,0	8,3	40,0	16,0	11,16 €
VHTM10-45/HDSS	M10	20,6	7,7	7,3	12,0	8,3	45,0	16,0	11,57 €
VHTM10-50/HDSS	M10	20,6	7,7	7,3	12,0	8,3	50,0	16,0	11,96 €
VHTM10-60/HDSS	M10	20,6	7,7	7,3	12,0	8,3	60,0	16,0	12,79 €
VHTM10-70/HDSS	M10	20,6	7,7	7,3	12,0	8,3	70,0	16,0	13,65 €
VHTM10-80/HDSS	M10	20,6	7,7	7,3	12,0	8,3	80,0	16,0	14,54 €

All dimensions in mm

## Our other products



CHAB

Hinge with stop,  
Hinge



HTD5M\_15

HTD Heavy duty  
timing pulley, HTD5  
Aluminium



PSG05

Spur gear - precision  
range, Pre-hardened  
Steel 35NCD6



GB5z

Cylindrical ballscrew  
nut, Cylindrical  
leadscrew nut



BAN

Angular clamp,  
Adjustable



PRF\_GAL

Roller for aluminium  
profile, Fixing kit for  
roller eccentric



INS

Self tapping steel  
insert, Steel



CHM63

Worm and wheel gear  
reducer, up to 196  
Nm



DER90

Stainless steel AC  
asynchronous motor  
1.1 - 1.5kW, 1.1 to  
1.5kW



BCA

Steel splined collar,  
Steel



PRF1945

Standard aluminium  
profile, 19 x 45 mm



HRV

V-rail guidance  
Simple Select®  
system, Rail with  
carriage

## Complementary products



RDS

Safety washer  
Hygienic Usit®,  
Stainless steel



DEP

Tools Hygienic Usit®  
and Hygienic  
Design®, Socket for  
mounting Hyg...