

- **Thin shaft bolts for use in hygienic environments**

- **Material:**

Stainless steel 1.4404 (316L)

Polished finish Ra<0.8


Advantages

- In combination with a clamping element, these thin shafted screws are designed against becoming detached accidentally, thus meeting the requirements of European standard 2006/42/EG
- Dirt and residues of product or cleaning materials will not remain, ensuring easy cleaning



Accessories

- RDS safety washer to secure the screw to the other component before assembly (see page 60)

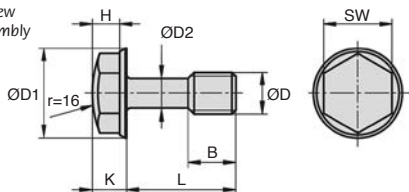

DISCOUNTS

Qty	1+	5+	10+	25+	50+
Disc.	Net	-5%	-10%	-15%	On request

Part N°	ØD	ØD1	ØD2	H	B	K	L	SW	Price each	
									1 to 4	
VHTM3-6/HDSS	M3	7,0	2,1	3,0	4,5	3,8	6,0	5,5		5,76 €
VHTM3-8/HDSS	M3	7,0	2,1	3,0	4,5	3,8	8,0	5,5		5,82 €
VHTM3-10/HDSS	M3	7,0	2,1	3,0	4,5	3,8	10,0	5,5		5,82 €
VHTM3-12/HDSS	M3	7,0	2,1	3,0	4,5	3,8	12,0	5,5		5,91 €
VHTM4-6/HDSS	M4	9,2	3,1	3,0	5,0	4,0	6,0	7,0		6,04 €
VHTM4-8/HDSS	M4	9,2	3,1	3,0	5,0	4,0	8,0	7,0		6,07 €
VHTM4-10/HDSS	M4	9,2	3,1	3,0	5,0	4,0	10,0	7,0		6,10 €
VHTM4-12/HDSS	M4	9,2	3,1	3,0	5,0	4,0	12,0	7,0		6,19 €
VHTM4-16/HDSS	M4	9,2	3,1	3,0	5,0	4,0	16,0	7,0		6,25 €
VHTM4-20/HDSS	M4	9,2	3,1	3,0	5,0	4,0	20,0	7,0		6,31 €
VHTM5-8/HDSS	M5	10,5	3,7	3,7	6,0	4,7	8,0	8,0		6,31 €
VHTM5-10/HDSS	M5	10,5	3,7	3,7	6,0	4,7	10,0	8,0		6,40 €
VHTM5-12/HDSS	M5	10,5	3,7	3,7	6,0	4,7	12,0	8,0		6,46 €
VHTM5-16/HDSS	M5	10,5	3,7	3,7	6,0	4,7	16,0	8,0		6,53 €
VHTM5-20/HDSS	M5	10,5	3,7	3,7	6,0	4,7	20,0	8,0		6,59 €
VHTM5-25/HDSS	M5	10,5	3,7	3,7	6,0	4,7	25,0	8,0		6,71 €

All dimensions in mm

Part N°	ØD	ØD1	ØD2	H	B	K	L	SW	Price each
									1 to 4
VHTM6-8/HDSS	M6	13,0	4,2	4,0	7,0	5,0	8,0	10,0	6,86 €
VHTM6-10/HDSS	M6	13,0	4,2	4,0	7,0	5,0	10,0	10,0	6,92 €
VHTM6-12/HDSS	M6	13,0	4,2	4,0	7,0	5,0	12,0	10,0	6,99 €
VHTM6-16/HDSS	M6	13,0	4,2	4,0	7,0	5,0	16,0	10,0	7,14 €
VHTM6-20/HDSS	M6	13,0	4,2	4,0	7,0	5,0	20,0	10,0	7,26 €
VHTM6-25/HDSS	M6	13,0	4,2	4,0	7,0	5,0	25,0	10,0	7,45 €
VHTM6-30/HDSS	M6	13,0	4,2	4,0	7,0	5,0	30,0	10,0	7,60 €
VHTM6-35/HDSS	M6	13,0	4,2	4,0	7,0	5,0	35,0	10,0	7,75 €
VHTM6-40/HDSS	M6	13,0	4,2	4,0	7,0	5,0	40,0	10,0	7,97 €
VHTM6-45/HDSS	M6	13,0	4,2	4,0	7,0	5,0	45,0	10,0	8,12 €
VHTM6-50/HDSS	M6	13,0	4,2	4,0	7,0	5,0	50,0	10,0	8,24 €
VHTM6-60/HDSS	M6	13,0	4,2	4,0	7,0	5,0	60,0	10,0	8,64 €
VHTM8-12/HDSS	M8	16,8	6,0	5,5	9,0	6,5	12,0	13,0	7,69 €
VHTM8-14/HDSS	M8	16,8	6,0	5,5	9,0	6,5	14,0	13,0	7,78 €
VHTM8-16/HDSS	M8	16,8	6,0	5,5	9,0	6,5	16,0	13,0	7,87 €
VHTM8-20/HDSS	M8	16,8	6,0	5,5	9,0	6,5	20,0	13,0	8,12 €
VHTM8-25/HDSS	M8	16,8	6,0	5,5	9,0	6,5	25,0	13,0	8,33 €
VHTM8-30/HDSS	M8	16,8	6,0	5,5	9,0	6,5	30,0	13,0	8,61 €
VHTM8-35/HDSS	M8	16,8	6,0	5,5	9,0	6,5	35,0	13,0	8,86 €
VHTM8-40/HDSS	M8	16,8	6,0	5,5	9,0	6,5	40,0	13,0	9,07 €
VHTM8-45/HDSS	M8	16,8	6,0	5,5	9,0	6,5	45,0	13,0	9,35 €
VHTM8-50/HDSS	M8	16,8	6,0	5,5	9,0	6,5	50,0	13,0	9,59 €
VHTM8-55/HDSS	M8	16,8	6,0	5,5	9,0	6,5	55,0	13,0	9,87 €
VHTM8-60/HDSS	M8	16,8	6,0	5,5	9,0	6,5	60,0	13,0	10,11 €
VHTM8-65/HDSS	M8	16,8	6,0	5,5	9,0	6,5	65,0	13,0	10,39 €
VHTM8-70/HDSS	M8	16,8	6,0	5,5	9,0	6,5	70,0	13,0	10,66 €
VHTM10-20/HDSS	M10	20,6	7,7	7,3	12,0	8,3	20,0	16,0	9,35 €
VHTM10-25/HDSS	M10	20,6	7,7	7,3	12,0	8,3	25,0	16,0	9,71 €
VHTM10-30/HDSS	M10	20,6	7,7	7,3	12,0	8,3	30,0	16,0	10,08 €
VHTM10-35/HDSS	M10	20,6	7,7	7,3	12,0	8,3	35,0	16,0	10,45 €
VHTM10-40/HDSS	M10	20,6	7,7	7,3	12,0	8,3	40,0	16,0	10,85 €
VHTM10-45/HDSS	M10	20,6	7,7	7,3	12,0	8,3	45,0	16,0	11,25 €
VHTM10-50/HDSS	M10	20,6	7,7	7,3	12,0	8,3	50,0	16,0	11,62 €
VHTM10-55/HDSS	M10	20,6	7,7	7,3	12,0	8,3	55,0	16,0	12,04 €
VHTM10-60/HDSS	M10	20,6	7,7	7,3	12,0	8,3	60,0	16,0	12,44 €
VHTM10-65/HDSS	M10	20,6	7,7	7,3	12,0	8,3	65,0	16,0	12,84 €
VHTM10-70/HDSS	M10	20,6	7,7	7,3	12,0	8,3	70,0	16,0	13,27 €
VHTM10-75/HDSS	M10	20,6	7,7	7,3	12,0	8,3	75,0	16,0	13,73 €
VHTM10-80/HDSS	M10	20,6	7,7	7,3	12,0	8,3	80,0	16,0	14,13 €

All dimensions in mm

Fax 0 825 88 6000
 Service 0,15 € / min
 + prix appel

Our other products



CMass
Eye bolt stainless steel, Stainless steel



PO
Pull handle - Multi-sector, Tapped recessed insert



ACLCHARJ
Hinge for aluminium profile, Adjusts in 2 directions



OP9
Mechanical digital position indicator, 5 numbers



E15
Right angle helical reducers, from 0.40 to 2.53 Nm



SHWbr
Washer - DIN125, Brass




Q6
Deep groove ball bearing, Steel



PM4
Worm and wheel set, Non hardened steel



 WS20
Drylin® W rail, Rail



FRss
Stainless steel thread inserts, Stainless steel



BEAS
Knob star grip antistatic, Star, antistatic



EP7
Electronic digital position indicator, 5 numbers

Complementary products



RDS
Safety washer Hygienic Usit®, Stainless steel



DEP
Tools Hygienic Usit® and Hygienic Design®, Socket for mounting Hyg...