
 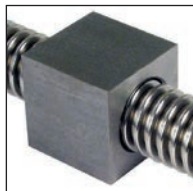


1 trapezoidal right or left-hand thread VKM VKMLH

- Right or left hand thread
- Thread conforms to NFE 03.616
- Material: Steel S300Pb
- Machined nut
- Thread tolerance: 7H



Accessories

- LFM steel leadscrew or
- LSM stainless steel leadscrew

DISCOUNTS ^A

Qty	1+	10+	20+	40+
Disc.	List	-30%	-40%	On request

DISCOUNTS ^B


Qté	1+	5+	10+
Rem.	List	-5%	On request

Part number	Ød	Pitch P	D	C	Weight (kg)	Stock*	Price each	
							1 to 9	40 to 59**
Right-hand thread								
VKM102	10	2	17	15	0,027	✓	A 2,94 €	A 1,77 €
VKM123	12	3	25	18	0,076	✓	A 5,09 €	A 3,06 €
VKM143	14	3	25	20	0,079	✓	A 6,00 €	A 3,60 €
VKM164	16	4	28	24	0,119	✓	A 6,41 €	A 3,85 €
VKM184	18	4	30	28	0,154	✓	A 7,53 €	A 4,52 €
VKM204	20	4	35	30	0,259	✓	A 8,50 €	A 5,10 €
VKM225	22	5	35	33	0,240	✓	A 10,56 €	A 6,33 €
VKM245	24	5	40	36	0,354	✓	A 11,88 €	A 7,13 €
VKM285	28	5	45	42	0,506	✓	A 14,94 €	A 8,96 €
VKM306	30	6	45	45	0,513	✓	A 17,38 €	A 10,42 €
VKM326	32	6	55	48	0,891	✓	A 25,61 €	A 15,37 €
VKM366	36	6	60	54	1,163	✓	B 23,01 €	B On request
VKM407	40	7	60	60	1,216	✓	B 28,75 €	B On request
VKM447	44	7	65	66	1,538	-	B 44,42 €	B On request
Left-hand thread								
VKM102/LH	10	2	17	15	0,027	✓	A 4,73 €	A 2,84 €
VKM123/LH	12	3	25	18	0,076	✓	A 6,23 €	A 3,74 €
VKM143/LH	14	3	25	20	0,079	✓	A 6,91 €	A 4,15 €
VKM164/LH	16	4	28	24	0,119	✓	A 7,57 €	A 4,55 €
VKM184/LH	18	4	30	28	0,154	✓	A 9,12 €	A 5,47 €
VKM204/LH	20	4	35	30	0,259	✓	A 10,25 €	A 6,15 €
VKM225/LH	22	5	35	33	0,240	✓	A 12,13 €	A 7,28 €
VKM245/LH	24	5	40	36	0,354	✓	A 13,60 €	A 8,16 €
VKM285/LH	28	5	45	42	0,506	-	A 17,38 €	A 10,42 €
VKM306/LH	30	6	45	45	0,513	-	A 20,98 €	A 12,59 €
VKM326/LH	32	6	55	48	0,891	-	A 30,17 €	A 18,10 €
VKM366/LH	36	6	60	54	1,163	-	B 27,37 €	B On request
VKM407/LH	40	7	60	60	1,216	-	B 35,28 €	B On request
VKM447/LH	44	7	65	66	1,538	-	B 53,32 €	B On request

*Depending on availability - Dimensions in mm

** refer to discounts

Our other products

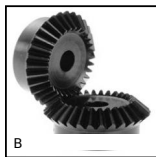

B
Steel bevel gear, 1:1



SH0
Parallel axis helical gear, Machined plastic (delrin)



TAC_SS
Stainless steel rigging screw (hook/eye), Stainless steel



BSM_LOK
Long-Lok spring plunger with internal hexagonal socket, LONG-LOK - s...



DZY
Cylindrical stop, Steel



BLHT70
Right angled gearbox, from 26 to 128 Nm



GAC
Lock for latch clamp, Strike plate



 
CABtool
Fitting cable tools, Crimping tools



BTCW
Cap for square tube to be welded, To be welded



TFR
Rigid manual tensioner, Fixed



B
Steel bevel gear, 1:1




NPTF30
Spacer for tube carrier, Fixing accessory Ø14 to Ø20

Complementary products



 
LFM
Steel leadscrew, Medium carbon steel - 1 thread



LSM
Stainless steel 316L leadscrew, Stainless steel - 1 thread



 LFM
Steel leadscrew, Medium carbon steel - 1 thread



LSM
Stainless steel 316L leadscrew, Stainless steel - 1 thread