

- One piece construction
- Operating elements
- Material: stainless steel 304
- Finish: polished

### Advantages

- Does not retain dirt or dust


### Applications

- Chemical, pharmaceutical and food industries

Solid stainless steel



Polished finish

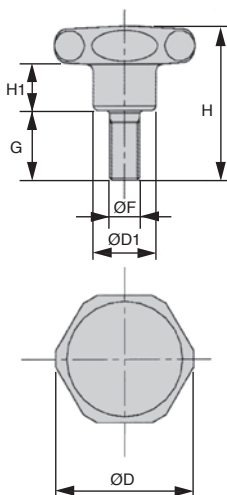

### DISCOUNTS

Qty	1+	6+	10+	25+
Disc. List		-5%	-10%	On request

Part number	ØF	ØD	ØD1	H	H1	G	Stock*	Price each 1 to 5
VML6-27	M6	27	15	30	10,0	10	✓	24,08 €
VML8-33	M8	33	19	43	11,0	20	✓	29,62 €
VML8-40	M8	40	21	47	15,0	20	✓	43,86 €
VML10-50	M10	50	25	63	17,5	30	✓	51,81 €
VML12-60	M12	60	27	77	20,0	40	✓	71,87 €

\*Depending on availability - Dimensions in mm

## Our other products



INS\_SS

Self tapping stainless steel insert, Stainless steel



VCMB

Dual-thread screw wood/metal, Steel




KS

Keysteel, Stainless steel - Keystock



RPP8

RPP heavy duty timing belt, RPP8

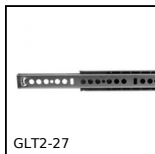


GLT2-27

Telescopic drawer runners for groove mounting, Partial extension



PLA

Flat magnet, Flat magnet

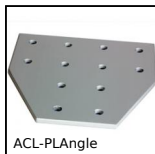

ACL-PLAngle

Joining plate for aluminium profile, Angle connection



SCA\_SS

Stainless steel flat cable clamp, Stainless steel



BWU

Compact precision slide, from 1510 N to 20000 N



CNA-CNG

Right angled mounting plate, Right



VTLM

3 lobed handle, Polyamide - Steel



BCA

Steel splined collar, Steel

## Complementary products



EML

Stainless steel hexagonal headed thumb nut, Lobed handscrew