

- One piece construction
- Operating elements
- Material: stainless steel 304
- Finish: polished

Advantages

- Does not retain dirt or dust


Applications

- Chemical, pharmaceutical and food industries

Solid stainless steel



Polished finish

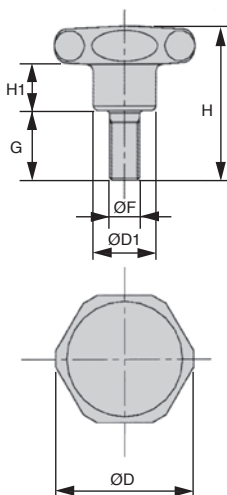

DISCOUNTS

Qty	1+	6+	10+	25+
Disc. List		-5%	-10%	On request

Part number	ØF	ØD	ØD1	H	H1	G	Stock*	Price each 1 to 5
VML6-27	M6	27	15	30	10,0	10	✓	24,08 €
VML8-33	M8	33	19	43	11,0	20	✓	29,62 €
VML8-40	M8	40	21	47	15,0	20	✓	43,86 €
VML10-50	M10	50	25	63	17,5	30	✓	51,81 €
VML12-60	M12	60	27	77	20,0	40	✓	71,87 €

*Depending on availability - Dimensions in mm


Our other products



Ball transfer unit light duty, Light



Right angle helical reducers, from 0.60 to 3.84 Nm

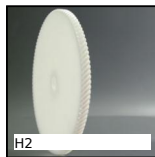

Crossed helical gear crossed axis at 90°, Machined plastic (delrin)



Open precision linear bearing, Precision - steel



V- rail guidance Simple Select® system, Rail with carriage



Stainless steel flanged bearing, Stainless steel



Swivel castor with central hole, Steel - Polyamide



Adjustable suction-cup support, Increased grip



Parallel axis helical gear, Machined plastic (delrin)



Fixed castor with plate, Steel - grey rubber



Shaft for linear guides, Hardened ground steel



Articulated bracket for use with aluminium profile, With clamping ha...

Complementary products



Stainless steel hexagonal headed thumb nut, Lobed handscrew