

- One piece construction
- Operating elements
- Material: stainless steel 304
- Finish: polished

### Advantages

- Does not retain dirt or dust


### Applications

- Chemical, pharmaceutical and food industries

Solid stainless steel



Polished finish

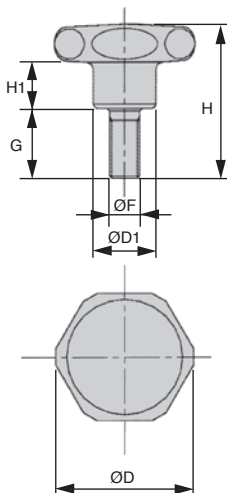

### DISCOUNTS

Qty	1+	6+	10+	25+
Disc. List		-5%	-10%	On request

Part number	ØF	ØD	ØD1	H	H1	G	Stock*	Price each 1 to 5
VML6-27	M6	27	15	30	10,0	10	✓	24,08 €
VML8-33	M8	33	19	43	11,0	20	✓	29,62 €
VML8-40	M8	40	21	47	15,0	20	✓	43,86 €
VML10-50	M10	50	25	63	17,5	30	✓	51,81 €
VML12-60	M12	60	27	77	20,0	40	✓	71,87 €

\*Depending on availability - Dimensions in mm

## Our other products



DOMI120

Domino 120 adjustable slide, Slide DOMILINE 120



VRC1

Retaining clamp, single sided, Single sided



LACM\_SS

Stainless steel cam lever, Female



AT5M AT10M

AT type timing belt per metre, AT5 Steel cored polyurethane



CLB\_M

Die cast zinc clamping lever - female, Zamak



HAS

Captive C washer, Slotted flat headed shoulder screw



NRV

Orthogonal support clamp, Orthogonal support clamp



LVT

Miniature motorised actuator 1A, 1 amper



GLT2-17

Telescopic drawer runners for groove



PSG05

Spur gear - precision range, Pre-hardened



ZG1

Plastic spur gear, Machined plastic



TS01\_TW01

Drylin® T linear slide, up to 7000 N

## Complementary products



EML

Stainless steel hexagonal headed thumb nut, Lobed handscrew