

- One piece construction
- Operating elements
- Material: stainless steel 304
- Finish: polished

Advantages

- Does not retain dirt or dust


Applications

- Chemical, pharmaceutical and food industries

Solid stainless steel



Polished finish

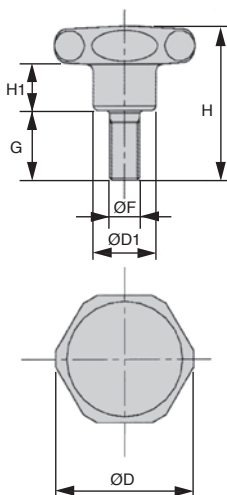

DISCOUNTS

Qty	1+	6+	10+	25+
Disc. List		-5%	-10%	On request

Part number	ØF	ØD	ØD1	H	H1	G	Stock*	Price each 1 to 5
VML6-27	M6	27	15	30	10,0	10	✓	24,08 €
VML8-33	M8	33	19	43	11,0	20	✓	29,62 €
VML8-40	M8	40	21	47	15,0	20	✓	43,86 €
VML10-50	M10	50	25	63	17,5	30	✓	51,81 €
VML12-60	M12	60	27	77	20,0	40	✓	71,87 €

*Depending on availability - Dimensions in mm

Our other products



Q3

Double row angular contact ball bearings, Angular contact - Steel



DB

Steel bevel gear, 2:1



MHWC

Double-disc flexible coupling, Double disk



PTA150

Articulated foot with pressed base, Ø 150



CHV

Mechanical motor drive, from 0,18 to 1,5kW



MEB

Plastic bevel gear, 1:1



BPTR_M

End cap with threaded insert for round tube, With threaded insert



BGC

Oldham coupling, Clamp



PGMT

Carrying handle, Stainless steel



BAG0

Locking rings in steel, Steel



PSG125S

Spur gear - precision range, Stainless steel 303



BLHB50

Right angled gearbox, bored shafts, up to 30 Nm

Complementary products



EML

Stainless steel hexagonal headed thumb nut, Lobed handscrew