


VMS

Threads M4-M10

- **Material:** Polished stainless steel 303
- Operating elements
- Conforms to DIN 464
- ** These thumb screws are supplied with shaft threaded along the entire length (no groove)

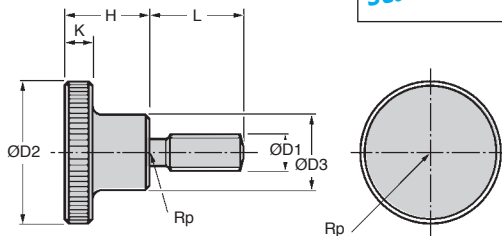

DISCOUNTS

Qty	1+	6+	20+	40+	60+	101+
Disc.	List	-10%	-15%	-20%	-25%	On request

Part number	ØD1	ØD2	ØD3	H	K	L	Stock*	Price each 1 to 5
VMS4-10	M4	16	8	9,5	3,5	10	✓	2,55 €
VMS4-16	M4	16	8	9,5	3,5	16	✓	2,82 €
VMS4-20	M4	16	8	9,5	3,5	20**	✓	3,08 €
VMS5-10	M5	20	10	11,5	4,0	10	✓	3,14 €
VMS5-16	M5	20	10	11,5	4,0	16	✓	3,73 €
VMS5-20	M5	20	10	11,5	4,0	20**	✓	4,50 €
VMS6-10	M6	24	12	15,0	5,0	10	✓	6,75 €
VMS6-16	M6	24	12	15,0	5,0	16	✓	5,25 €
VMS6-20	M6	24	12	15,0	5,0	20	✓	9,50 €
VMS6-25	M6	24	12	15,0	5,0	25**	✓	7,71 €
VMS8-16	M8	30	16	18,0	6,0	16	✓	12,01 €
VMS8-20	M8	30	16	18,0	6,0	20	✓	13,02 €
VMS8-25	M8	30	16	18,0	6,0	25	✓	12,36 €
VMS10-20	M10	36	20	23,0	8,0	20	✓	18,28 €
VMS10-25	M10	36	20	23,0	8,0	25	✓	20,57 €

*Depending on availability - Dimensions in mm

Our other products



SDC
Positioning sleeve for indexing pin, For pin Ø4 to Ø12



HTD14M_85
HTD Heavy duty timing pulley, HTD14 Cast



PSG15
Spur gear - precision range, Case hardened steel 20NCD2



HAS
Captive C washer, Slotted flat headed shoulder screw



PTA50
Articulated levelling foot, pressed base Ø50, Ø 50



NJM
Multiple junction clamp, Multiple



DOG111
Motor-gearbox 12V and 24V DC, from 1.5 to 6 Nm



DKONSL
Silicone conical elasto buffer, Male mounting



BFM
Flanged bronze nut, Bronze - 1 thread



RCC_RCX
Spherical tilt washer - DIN6319, concave



DOMI120
Domino 120 adjustable slide, Slide DOMILINE 120 with



BEK
Bearing housing for miniature ballscrew, Bearing housing

Complementary products



EMS
Stainless steel knurled thumb nut, Knurled