


## VMS

## Threads M4-M10

- **Material:** Polished stainless steel 303
- Operating elements
- Conforms to DIN 464
- \*\* These thumb screws are supplied with shaft threaded along the entire length (no groove)

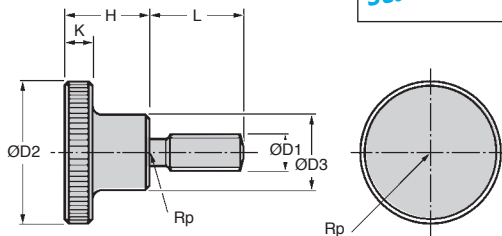

### DISCOUNTS

Qty	1+	6+	20+	40+	60+	101+
Disc.	List	-10%	-15%	-20%	-25%	On request

Part number	ØD1	ØD2	ØD3	H	K	L	Stock*	Price each 1 to 5
VMS4-10	M4	16	8	9,5	3,5	10	✓	2,55 €
VMS4-16	M4	16	8	9,5	3,5	16	✓	2,82 €
VMS4-20	M4	16	8	9,5	3,5	20**	✓	3,08 €
VMS5-10	M5	20	10	11,5	4,0	10	✓	3,14 €
VMS5-16	M5	20	10	11,5	4,0	16	✓	3,73 €
VMS5-20	M5	20	10	11,5	4,0	20**	✓	4,50 €
VMS6-10	M6	24	12	15,0	5,0	10	✓	6,75 €
VMS6-16	M6	24	12	15,0	5,0	16	✓	5,25 €
VMS6-20	M6	24	12	15,0	5,0	20	✓	9,50 €
VMS6-25	M6	24	12	15,0	5,0	25**	✓	7,71 €
VMS8-16	M8	30	16	18,0	6,0	16	✓	12,01 €
VMS8-20	M8	30	16	18,0	6,0	20	✓	13,02 €
VMS8-25	M8	30	16	18,0	6,0	25	✓	12,36 €
VMS10-20	M10	36	20	23,0	8,0	20	✓	18,28 €
VMS10-25	M10	36	20	23,0	8,0	25	✓	20,57 €

\*Depending on availability - Dimensions in mm

## Our other products



AT5M AT10M

AT type timing belt per metre, AT5 Steel cored polyurethane



MHWC

Double-disc flexible coupling, Double disk



BEAS

Star shaped anti-static handle, Star, anti-static



SEV

Vertical stirrup toggle clamp, Vertical Latch Clamp - stainless steel



SH0

Parallel axis helical gear, Machined plastic (delrin)



PCS\_PA6

Plastic sprocket, 12.7mm (DIN 08B-1)



DCG

Suction cup, 2.5 bellows, nitrile



 
PENV

Recessed handle, screw fixing



BPM

Slotted spring plunger with ball tip, Steel



GPLac

Brush, steel



BLHM60

Right angled gearbox, double output shafts, up to 70 Nm



SDC

Positioning sleeve for indexing pin, For pin Ø4 to Ø12

## Complementary products



EMS

Stainless steel knurled thumb nut, Knurled