

Small 6 lobe threaded handle



VP

Black Duroplast, steel thread


- **Operating element**
- **Materials:**
Black phenolic Duraplaxt
Threaded stud: chromed steel

Good resistance



Advantages

- Easy grip
- Temperature resistant
- Good chemical resistance
- Easier to clean that technopolymer
- In machining applications, less likely to retain swarf

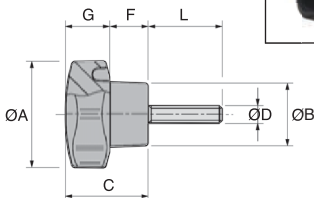

DISCOUNTS

Qty	1+	10+	20+	50+	100+	200+
Disc. List	-5%	-10%	-15%	-20%		On request

Part number	ØA	ØB	C	ØD	F	G	L	Weight (g)	Price each 1 to 9
VP20-M4-15	20	13	15	M4	7	8	15	5	2,73 €
VP20-M4-25	20	13	15	M4	7	8	25	6	2,73 €
VP20-M5-15	20	13	15	M5	7	8	15	7	2,95 €
VP20-M5-25	20	13	15	M5	7	8	25	8	3,02 €
VP20-M6-15	20	13	15	M6	7	8	15	8	2,95 €
VP20-M6-25	20	13	15	M6	7	8	25	11	3,02 €
VP30-M6-15	30	17	24	M6	11	13	15	18	3,46 €
VP30-M6-25	30	17	24	M6	11	13	25	21	3,54 €
VP30-M6-35	30	17	24	M6	11	13	35	23	3,61 €
VP30-M8-20	30	17	24	M8	11	13	20	25	3,73 €
VP30-M8-30	30	17	24	M8	11	13	30	27	3,73 €
VP40-M8-20	40	21	28	M8	13	15	20	38	4,61 €
VP40-M8-30	40	21	28	M8	13	15	30	40	4,68 €
VP40-M8-40	40	21	28	M8	13	15	40	44	4,75 €
VP50-M8-20	50	25	33	M8	15	18	20	52	5,37 €
VP50-M8-30	50	25	33	M8	15	18	30	56	5,41 €
VP50-M8-40	50	25	33	M8	15	18	40	60	5,41 €
VP50-M10-20	50	25	33	M10	15	18	20	61	5,48 €
VP50-M10-30	50	25	33	M10	15	18	30	65	5,63 €
VP50-M10-40	50	25	33	M10	15	18	40	70	6,00 €
VP60-M12-20	60	28	35	M12	15	20	20	101	7,56 €
VP60-M12-30	60	28	35	M12	15	20	30	107	7,71 €
VP60-M12-40	60	28	35	M12	15	20	40	115	7,75 €
VP70-M12-30	70	32	42	M12	21	21	30	133	9,29 €
VP70-M12-40	70	32	42	M12	21	21	40	138	9,44 €
VP70-M12-50	70	32	42	M12	21	21	50	145	9,58 €
VP70-M14-50	70	32	42	M14	21	21	50	181	13,20 €

Dimensions in mm

Our other products



SH2

Parallel axis helical gear, Steel 20NCD2



F7-I

Multifunction display, With internal sensor



GPBSS

Threaded spherical knob, Stainless steel 304



BLM

Spring loaded plunger with ball tip, Stainless steel body




M0

Worm and wheel set, Hardened steel




SH1

 Parallel axis helical gear, Steel 20NCD2



KM

Bearing locknut, Locknut KM

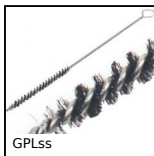

GPLss

Brush, stainless steel



BAG-MI

Split shaft collar with clamp lever, Steel



GE

Toggle latches, Standard



SLB

Indexing plunger, steel class 5.8



DB

Steel bevel gear, 2:1

Complementary products



GLP

Small 6 lobe threaded handle - male, Technopolymer - Steel



VPSS

Small 6 lobe threaded handle - male, Duroplast - Stainless steel