


VPPTss

304 stainless steel

- Handwheel with rotating handle
- Finish: turned, natural
- Solid hub with centering point
- Material:
1.4301 stainless steel

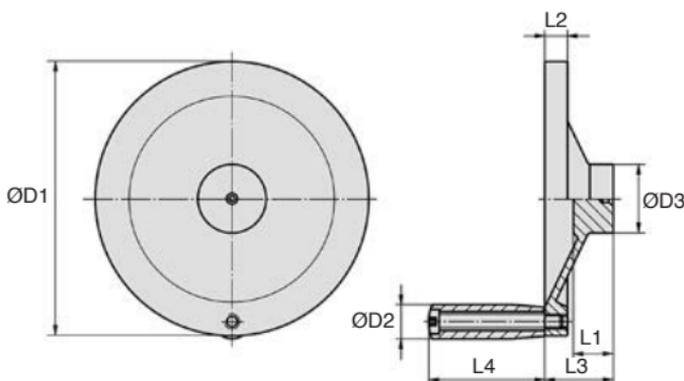

DISCOUNTS

Qty	1+	3+	5+	10+
Disc.	List	-5%	-10%	On request

Part N°	ØD1	ØD2	ØD3	L1	L2	L3	L4	Price each
								1 to 2
VPPT76/SS	76,20	9,91	22,1	17,02	6,10	27,9	37,90	62,88 €
VPPT101/SS	101,60	11,94	25,9	18,03	7,87	31,7	39,88	70,64 €
VPPT151/SS	152,40	19,05	38,1	22,10	12,70	38,1	63,50	140,56 €
VPPT203/SS	203,20	22,10	45,7	24,13	14,22	45,7	76,20	181,08 €
VPPT254/SS	254,00	22,10	50,8	26,67	15,75	50,8	76,20	282,93 €

All dimensions in mm

Fax 0 825 88 6000
Service 0,15 € / min
+ prix appel

Our other products



CF
Cam follower,
Standard - steel



CLM
Male clevis end, Steel
short




HTD5M_25
HTD Heavy duty
timing pulley, HTD5
Steel



PDM_PDV
Detectable plastic
palm grip, by metal
detectors




VTA
Vari-Tork® slip
friction clutch, 0.53 to
1.32 Nm

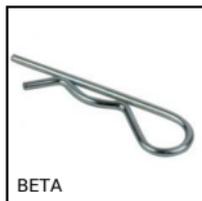

BETA
Hitch pin, Hitch



GLB
Small 6 lobe female
handle,
Technopolymer -
Brass

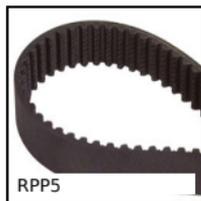

RPP5
RPP heavy duty
timing belt, RPP5



RDCss
Rigging screw with 2
jaws stainless steel,



CHINV
Invisible hinge,
Invisible - Opening up



MFBC
Flexible Bellows
coupling, Aluminium



HG8-ECO
Eco range Spur gear,
Steel C45

Complementary products



HLUss
Spoked handwheel,
Stainless steel 316



SHA
Handwheel without
handle, Polyamide



SHA_PT
Handwheel with
handle, Polyamide



SHA_PTR
Handwheel with
folding handle,
Polyamide