


VPPTss

304 stainless steel

- Handwheel with rotating handle
- Finish: turned, natural
- Solid hub with centering point
- Material:
1.4301 stainless steel

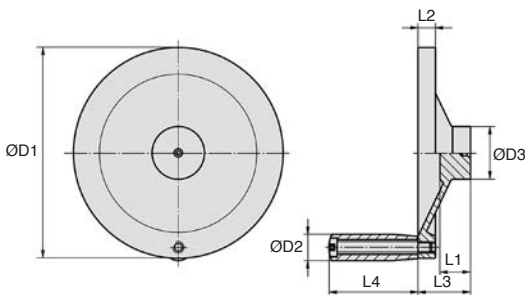

DISCOUNTS

Qty	1+	3+	5+	10+
Disc.	List	-5%	-10%	On request

Part N°	ØD1	ØD2	ØD3	L1	L2	L3	L4	Price each
								1 to 2
VPPT76/SS	76,20	9,91	22,1	17,02	6,10	27,9	37,90	62,88 €
VPPT101/SS	101,60	11,94	25,9	18,03	7,87	31,7	39,88	70,64 €
VPPT151/SS	152,40	19,05	38,1	22,10	12,70	38,1	63,50	140,56 €
VPPT203/SS	203,20	22,10	45,7	24,13	14,22	45,7	76,20	181,08 €
VPPT254/SS	254,00	22,10	50,8	26,67	15,75	50,8	76,20	282,93 €

 
All dimensions in mm

Fax 0 825 88 6000
Service 0,15 € / min
+ prix appel


Our other products



JSM
Cylindrical polymer bush, Universal polymer



 INO
Internal gear, Machined plastic (delrin)



MRS
Stainless steel metric section rack, Stainless steel



CHAR16046
Spring hinge, screwed



BTE
Universal tension arm, For standard applications



CHA35
Hinge for aluminium profile, Hinge



PAMF80EB
Articulated foot with sheet metal base Ø80, Articulated foot



EHD12
Internal epicyclic servo reducers, from 60 to 140 Nm



GTC
Belt tensioner, For standard applications



SBS_L
Chain link, Stainless steel



KKP-AR
Linear bearing with inclined ball tracks, Heavy loads / -20°



CAP805
Slat top chain stainless steel, Large range 805

Complementary products



HLUss
Spoked handwheel, Stainless steel 316



SHA
Handwheel without handle, Polyamide



SHA_PT
Handwheel with handle, Polyamide



SHA_PTR
Handwheel with folding handle, Polyamide