


## VPPTss

304 stainless steel

- Handwheel with rotating handle
- Finish: turned, natural
- Solid hub with centering point
- Material:  
1.4301 stainless steel

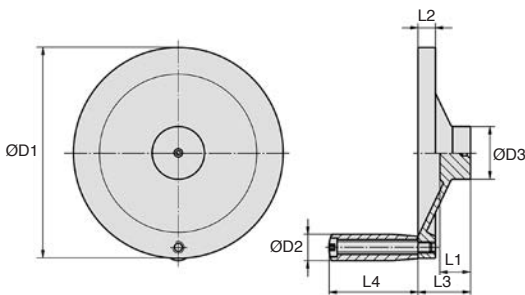

### DISCOUNTS

Qty	1+	3+	5+	10+
Disc.	List	-5%	-10%	On request

Part N°	ØD1	ØD2	ØD3	L1	L2	L3	L4	Price each
								1 to 2
VPPT76/SS	76,20	9,91	22,1	17,02	6,10	27,9	37,90	62,88 €
VPPT101/SS	101,60	11,94	25,9	18,03	7,87	31,7	39,88	70,64 €
VPPT151/SS	152,40	19,05	38,1	22,10	12,70	38,1	63,50	140,56 €
VPPT203/SS	203,20	22,10	45,7	24,13	14,22	45,7	76,20	181,08 €
VPPT254/SS	254,00	22,10	50,8	26,67	15,75	50,8	76,20	282,93 €

All dimensions in mm

**Fax** 0 825 88 6000  
Service 0,15 € / min  
+ prix appel

## Our other products



BH01  
Single housed bearing, Bearing fitted with adhesive



SHA\_PTR  
Handwheel with folding handle, Polyamide



HCA  
Magnetic screw with socket, Steel



CHTRB  
Single and dual output gearboxes, Up to 16,5 Nm



BSCm  
Knurled torque knobs - male, Knurled threaded torque



MSP23  
Masterplate® glueable insert Ø23, Cylindrical Ø23 with threaded s...



CHB  
Worm and wheel gear reducer, up to 22 Nm



CHAFR-MINI  
Miniature friction hinge, Friction



WJUM16  
Drylin® W bearing block, Slide



RCC\_RCX  
Spherical tilt washer - DIN6319, concave

 


GCA  
Linch pin, Linch



BOX-CSss  
Hose clamp, Box set of stainless steel hose clamps

## Complementary products



HLUss  
Spoked handwheel, Stainless steel 316



SHA  
Handwheel without handle, Polyamide



SHA\_PT  
Handwheel with handle, Polyamide



SHA\_PTR  
Handwheel with folding handle, Polyamide