


VPPTss

304 stainless steel

- Handwheel with rotating handle
- Finish: turned, natural
- Solid hub with centering point
- Material:
1.4301 stainless steel

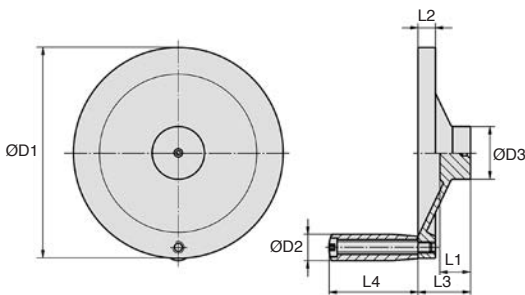

DISCOUNTS

Qty	1+	3+	5+	10+
Disc.	List	-5%	-10%	On request

Part N°	ØD1	ØD2	ØD3	L1	L2	L3	L4	Price each
								1 to 2
VPPT76/SS	76,20	9,91	22,1	17,02	6,10	27,9	37,90	62,88 €
VPPT101/SS	101,60	11,94	25,9	18,03	7,87	31,7	39,88	70,64 €
VPPT151/SS	152,40	19,05	38,1	22,10	12,70	38,1	63,50	140,56 €
VPPT203/SS	203,20	22,10	45,7	24,13	14,22	45,7	76,20	181,08 €
VPPT254/SS	254,00	22,10	50,8	26,67	15,75	50,8	76,20	282,93 €

All dimensions in mm

Fax 0 825 88 6000
Service 0,15 € / min
+ prix appel

Our other products



Pull handle - Multi-sector, Tapped recessed insert



 
Ball pin lifting ring, Steel



T type timing belt per metre, T10 Steel cored polyurethane



Right angled gearbox, from 26 to 70 Nm



Sealing washer Hygienic Usit®, Stainless steel - White EPDM



Hinge without pin, Plastic hinge



Swivel castor with central hole, Steel - Polyamide



Angular contact ball bearing, Steel



Accessories, Clamping lever



Strike for toggle latch, 25.5mm



Right angle spiro bevel gearbox, Up to 182Nm



Square Tube, Aluminium or Stainless steel

Complementary products



Spoked handwheel, Stainless steel 316



Handwheel without handle, Polyamide



Handwheel with handle, Polyamide



Handwheel with folding handle, Polyamide