


VPPTss

304 stainless steel

- Handwheel with rotating handle
- Finish: turned, natural
- Solid hub with centering point
- Material:
1.4301 stainless steel

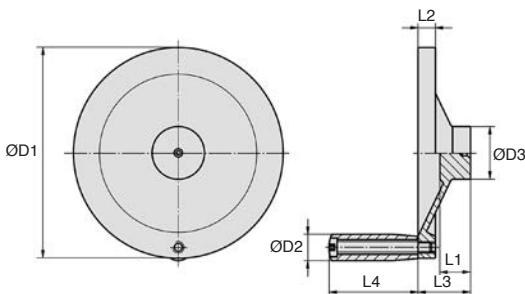

DISCOUNTS

Qty	1+	3+	5+	10+
Disc.	List	-5%	-10%	On request

Part N°	ØD1	ØD2	ØD3	L1	L2	L3	L4	Price each
								1 to 2
VPPT76/SS	76,20	9,91	22,1	17,02	6,10	27,9	37,90	62,88 €
VPPT101/SS	101,60	11,94	25,9	18,03	7,87	31,7	39,88	70,64 €
VPPT151/SS	152,40	19,05	38,1	22,10	12,70	38,1	63,50	140,56 €
VPPT203/SS	203,20	22,10	45,7	24,13	14,22	45,7	76,20	181,08 €
VPPT254/SS	254,00	22,10	50,8	26,67	15,75	50,8	76,20	282,93 €

All dimensions in mm

Fax 0 825 88 6000
Service 0,15 € / min
+ prix appel

Our other products



F7-P-AM
Multifunction display,
Magnetic ring



T10_21_AL
T type timing pulley,
Economy range - T10
aluminium



AT5-16ECO
AT type timing pulley,
Economy range - AT5
aluminium




AK
Bellows coupling
Gerwah®, from 36 to
800Nm



FRtool
Tool for thread repair
inserts, Assembly tool



 VRC2
Retaining clamp, dual
sided, Dual sided



SBF
Sealed flange bearing
unit for Food Industry,
cover



TBD
Manual leadscrew
table with opposing
threads, 40kg



RT25ss
Self-centering flanged
locking assembly,
Medium/high torque



BABtss
303 Stainless steel
ball pin, 303 Stainless
steel

 


FB_ECO
Eco. range steel bevel
gear, 4:1



LWL
Linear ball slide -
Stainless steel balls,
Chariot - from 514 N
to 1...

Complementary products



HLUss
Spoked handwheel,
Stainless steel 316



SHA
Handwheel without
handle, Polyamide



SHA_PT
Handwheel with
handle, Polyamide



SHA_PTR
Handwheel with
folding handle,
Polyamide