


## VPPTss

304 stainless steel

- Handwheel with rotating handle
- Finish: turned, natural
- Solid hub with centering point
- Material:  
1.4301 stainless steel

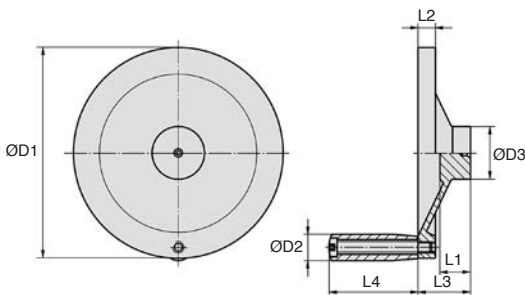

### DISCOUNTS

Qty	1+	3+	5+	10+
Disc.	List	-5%	-10%	On request

Part N°	ØD1	ØD2	ØD3	L1	L2	L3	L4	Price each
								1 to 2
VPPT76/SS	76,20	9,91	22,1	17,02	6,10	27,9	37,90	62,88 €
VPPT101/SS	101,60	11,94	25,9	18,03	7,87	31,7	39,88	70,64 €
VPPT151/SS	152,40	19,05	38,1	22,10	12,70	38,1	63,50	140,56 €
VPPT203/SS	203,20	22,10	45,7	24,13	14,22	45,7	76,20	181,08 €
VPPT254/SS	254,00	22,10	50,8	26,67	15,75	50,8	76,20	282,93 €

All dimensions in mm

**Fax** 0 825 88 6000  
Service 0,15 € / min  
+ prix appel

## Our other products



G0

Steel spur gear, Steel 20NCD2



PRF\_FIX\_ANG

Fastener for aluminium profile, Angular joint



ESCON

Speed controller 5A accessories, Kit of 4 cables for DC motor



H1

Crossed helical gear crossed axis at 90°, Steel 20NCD2



CHAFR

Adjustable friction hinges, Friction



ACL-PR

Joining plate for aluminium profile, Right angled connection



CDC

Conical compression spring, Conical



PAL

Self locking counter nut, For axial locking



T5M\_T10M

T type timing belt per metre, T10 Steel



GMK17\_BR

Clamp for guiding profile, Rounded only



ACLEPP

 
Right angled bracket for aluminium profile,



DB

Steel bevel gear, 2:1

## Complementary products



HLUss

Spoked handwheel, Stainless steel 316



SHA

Handwheel without handle, Polyamide



SHA\_PT

Handwheel with handle, Polyamide



SHA\_PTR

Handwheel with folding handle, Polyamide