

Hand wheel with rotating handle



VPRA_M

Thermosetting plastic

- Hand wheel with handle for manual use

- Pre-bored
- Working temperature: -20°C to +140°C

- Materials:

- Wheel: thermosetting plastic
- Hub: galvanised steel or stainless steel
- Handle: thermosetting plastic
- Axle: galvanised steel




Options

- Different bore diameters
- Keyway
- See modification info

Application

- All types of machines

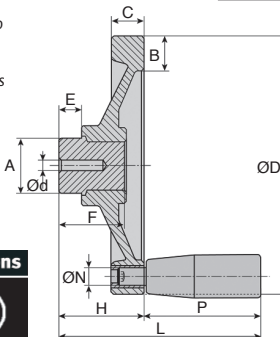

Bore modifications



DISCOUNTS

Qty	1+	6+	20+
Disc.	List	-5%	On request

Part number	ØD	H	L	C	B	ØA	Ød	E	F	P	ØN	Stock*	Price each 1 to 5
Steel													
VPRA50-M	50	23	50	11	10	16	4	9	20	13x27	M6	✓	16,05 €
VPRA65-M	65	28	55	13	13	20	4	10	24	13x27	M6	✓	18,66 €
VPRA80-M	80	31	71	14	15	20	4	10	27	17x40	M6	✓	20,48 €
VPRA100-M	100	35	85	14	16	24	4	11	29	21x50	M8	✓	25,30 €
VPRA125-M	125	44	99	16	18	32	6	13	35	23x55	M8	✓	32,48 €
VPRA150-M	150	48	113	18	20	32	6	13	37	25x65	M10	✓	39,91 €
VPRA200-M	200	58	143	21	24	40	6	16	44	28x85	M10	✓	63,04 €
VPRA250-M	250	66	151	22	30	48	6	17	49	28x85	M10	-	89,27 €
VPRA300-M	300	76	161	24	35	58	6	18	55	28x85	M10	-	138,16 €
Stainless steel													
VPRA100-M/SS	100	35	85	14	16	24	4	11	29	21x50	M8	-	44,21 €
VPRA150-M/SS	150	48	113	18	20	32	6	13	37	25x65	M10	-	58,95 €
VPRA200-M/SS	200	58	143	21	24	40	6	16	44	28x85	M10	-	86,02 €

*Subject to availability - Dimensions in mm

Our other products



SLV

Vertical toggle clamp,
Vertical Lever Clamp -
steel



PGT

Sliding profile, Sliding
panel support



PRF JL5

Lip seal for panel,
Door seal - \varnothing 5mm



CDGamme

Compression spring
DIN2095, DIN 2095



PCatherm

Pull handle,
Thermoplastic



CNA-CNG

Right angled
mounting plate, Right
angled mounting
plate for clevis



CLSCLP_SS

Clevis components,
short version,
Stainless steel - short
range



CFF

Female rod ends DIN
ISO12240-4, Steel /
bronze



SBS_L

Chain link, Stainless
steel



SVG

Adjustable latch
clamp with strike
plate, Stroke from
106,7mm to 121...



H1

Crossed helical gear
crossed axis at 90°,
Steel 20NCD2



TM_CTM_CTF

Suction cup threaded
insert, Insert for
suction cup - Tread
click-in

Complementary products



MHQMEP

Arm with rotating
handle, Square bore



V3RA_PT

3-spoked handwheel
with handle,
Polyamide



SHA_PTR

Handwheel with
folding handle,
Polyamide



PGR

Folding revolving
handle for handwheel,
Folding