

Quarter-turn clamp lock

VQT

Plastic or stainless steel button

- **Quarter-turn lock with handle**
- Locking element
- Materials:
 - Nickel-plated steel body
 - Steel pins
 - Button in black glass fiber reinforced PA or stainless steel
- Working T°
 - Plastic button +130°C max.
 - Stainless steel button +200°C max.

Advantages


- Allows locking or unlocking without tools and without quarter-turn screws.
- Lock On/Off display.
- Saves time by avoiding the handling of tools.

Infos


- The M2 or M3 fixing screws are supplied
- Mounting option A for 6mm to 12 mm plates.
- Mounting option B for 12 to 20mm plates.
- The specified forces apply only for use with the VQT PLQ sleeves.

Accessories


- Clamping plates VQT-PLQ

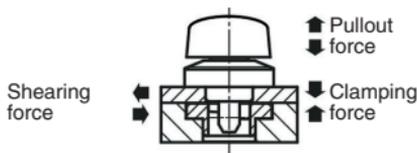


Use

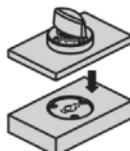

 Make sure the handle is in the "OFF" position.




 
Press the pin of the quarter-turn lock into the clamping plate.



To lock the components, turn the handle to the "ON" position. A click indicates the opening/closing

Part number	Clamping force (N)	Resistance shearing (kN)	Pullout force (kN)	Dimensions (mm)		
				H	H1	ØM
Plastic button						
VQT5-15/PA	60	1,8	1,2	19,0	6,5	M2x3
VQT8-17/PA	90	3,2	2,6	26,0	10,0	M3x4
VQT8-23/PA	90	3,2	2,6	26,0	10,0	M3x4
Stainless steel button						
VQT5-15/SS	60	1,8	1,2	19,0	6,5	M2x3
VQT8-17/SS	90	3,2	2,6	25,5	10,0	M3x4
VQT8-23/SS	90	3,2	2,6	25,5	10,0	M3x4

*Depending on availability - Dimensions in mm

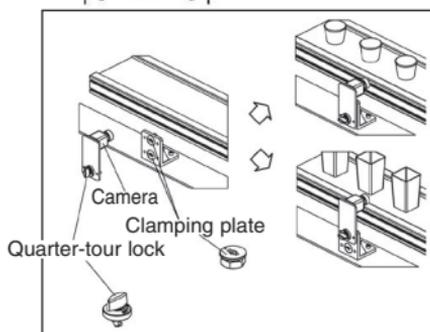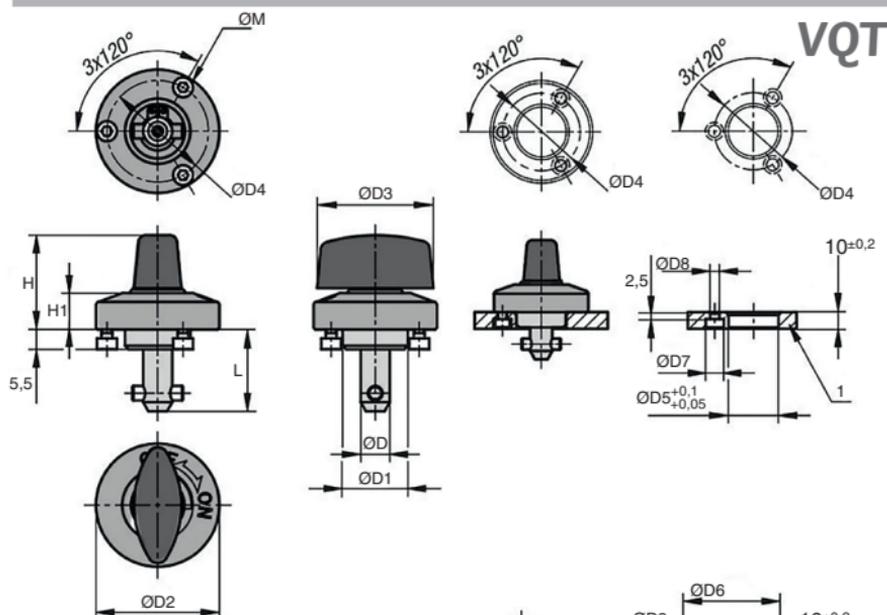

Example of use:
change the positions of the camera

DISCOUNTS

Qty	1+	4+	8+
Disc.	List	-5%	On request

Part number	ØD	L	ØD1	ØD2	ØD3	ØD4	ØD5	ØD6	ØD7	ØD8	T	T1	Price each
													1 to 3
Plastic button													
VQT5-15/PA	5	15,5	14	25	20	21	14	26	4,4	2,4	6	6-10	47,70 €
VQT8-17/PA	8	17,0	18	34	32	28	18	35	6,5	3,4	6	6-14	49,06 €
VQT8-23/PA	8	23,0	18	34	32	28	18	35	6,5	3,4	12	12-20	49,06 €
Stainless steel button													
VQT5-15/SS	5	15,5	14	25	20	21	14	26	4,4	2,4	6	6-10	59,96 €
VQT8-17/SS	8	17,0	18	34	32	28	18	35	6,5	3,4	6	6-14	62,69 €
VQT8-23/SS	8	23,0	18	34	32	28	18	35	6,5	3,4	12	12-20	62,69 €

*Depending on availability - Dimensions in mm

Quarter-turn clamp lock - Clamping plate


VQTPLQ/P

Wall mounting

- Clamping plate for VQT quarter-turn lock
- Mounting for plate thickness 6 to 10mm.
- Materials:
 - Nickel-plated steel body
 - Stainless steel nut

Accessories

- VQT quarter-tour lock

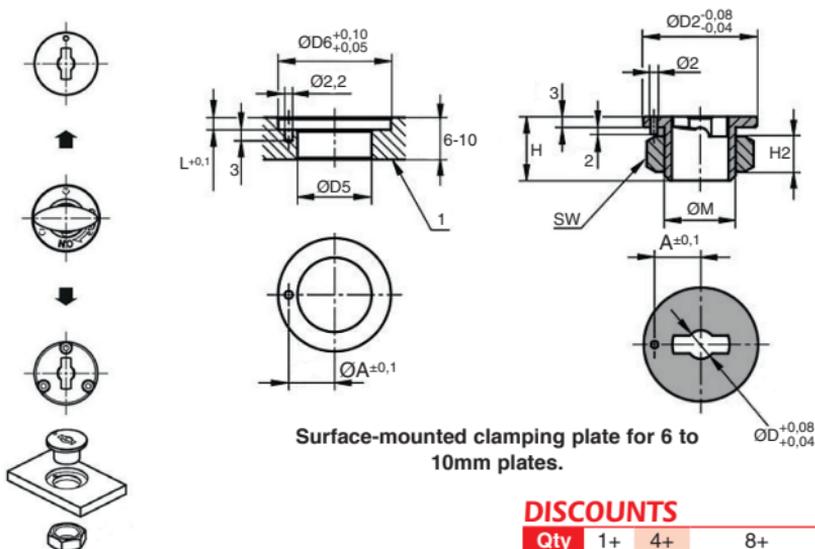

Surface-mounted clamping plate for 6 to 10mm plates.

DISCOUNTS

Qty	1+	4+	8+
Disc.	List	-5%	On request

Part number	ØD	ØD2	ØD4	A	M	H2	SW
VQT5-PLQ/P	5	25	21	10,5	M14X1,5	8	22
VQT8-PLQ/P	8	32	26	13,0	M20X1,5	10	30

Part number	H	H1	ØD5	ØD6	L	Price each
						1 to 3
VQT5-PLQ/P	16	4,5	15	25	3,5	47,70 €
VQT8-PLQ/P	18	5,5	21	32	3,5	49,06 €

*Depending on availability - Dimensions in mm

Quarter-turn clamp lock - Clamping plate

Flush mounting

VQTPLQ/N


- Clamping plate for VQT quarter-turn lock
- Mounting for plate thickness over 10mm.
- Materials:
Nickel-plated steel body

Infos

- The M2 or M3 fixing screws are supplied

Accessories

- VQT quarter-turn lock

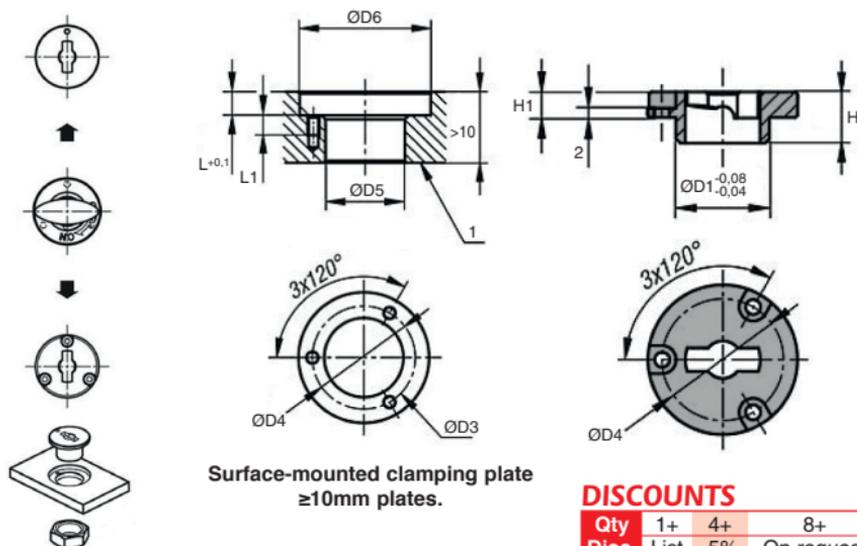

DISCOUNTS

Qty	1+	4+	8+
Disc.	List	-5%	On request

Part number	ØD	ØD1	ØD2	ØD4	H2	SW
VQT5-PLQ/N	5	14	25	21	8	22
VQT8-PLQ/N	8	20	32	26	10	30

Part number	ØD3 for screw							Price each 1 to 3
	H	H1	DIN912	ØD5	ØD6	L	L1	
VQT5-PLQ/N	9	4,5	M2	14	26	5	4	21,39 €
VQT8-PLQ/N	11	5,5	M3	20	33	6	5	22,73 €

*Depending on availability - Dimensions in mm

Our other products



M2

Worm, Unhardened steel



AZY_SS

Stainless steel cylindrical elastomount, Stainless steel



PSG35

Spur gear - precision range, Stainless steel 303



PRF_ART

Articulated bracket for use with aluminium profile, With clamping ha...




NPTF30

Spacer for tube carrier, Fixing accessory Ø14 to Ø20



ZG0

Plastic spur gear, Machined plastic (delrin)

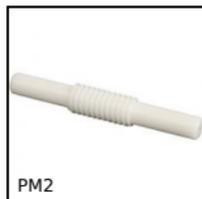

PM2

Worm, Machined plastic (delrin)



PSG25

Spur gear - precision range, Stainless steel 316



CLSCLP_SS

Clevis components, short version, Stainless steel - short



CM_CO

Tools Hygienic Usit® and Hygienic Design®, Protective



UGAC_UGET

Actuator guide kit, Coupling for threaded cylinder end



PTRSS

Idler chain sprocket, For hostile environments

Complementary products



VQTplqn

Quarter-turn clamp lock - Clamping plate, Flush mounting



VQT

Quarter-turn clamp lock, Plastic or stainless steel button