

Quarter-turn clamp lock

VQT

Plastic or stainless steel button

- **Quarter-turn lock with handle**
- Locking element
- Materials:
 - Nickel-plated steel body
 - Steel pins
 - Button in black glass fiber reinforced PA or stainless steel
- Working T°
 - Plastic button +130°C max.
 - Stainless steel button +200°C max.

Advantages

 
- Allows locking or unlocking without tools and without quarter-turn screws.
- Lock On/Off display.
- Saves time by avoiding the handling of tools.

Infos


- The M2 or M3 fixing screws are supplied
- Mounting option A for 6mm to 12 mm plates.
- Mounting option B for 12 to 20mm plates.
- The specified forces apply only for use with the VQT PLQ sleeves.

Accessories


- Clamping plates VQT-PLQ



Use

 

 Make sure the handle is in the "OFF" position.





Press the pin of the quarter-turn lock into the clamping plate.



To lock the components, turn the handle to the "ON" position. A click indicates the opening/closing

	Clamping force (N)	Resistance shearing (kN)	Pullout force (kN)	H	H1	ØM
Plastic button						
VQT5-15/PA	60	1,8	1,2	19,0	6,5	M2x3
VQT8-17/PA	90	3,2	2,6	26,0	10,0	M3x4
VQT8-23/PA	90	3,2	2,6	26,0	10,0	M3x4
Stainless steel button						
VQT5-15/SS	60	1,8	1,2	19,0	6,5	M2x3
VQT8-17/SS	90	3,2	2,6	25,5	10,0	M3x4
VQT8-23/SS	90	3,2	2,6	25,5	10,0	M3x4

*Depending on availability - Dimensions in mm

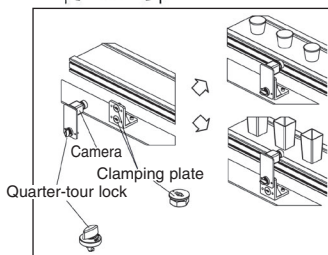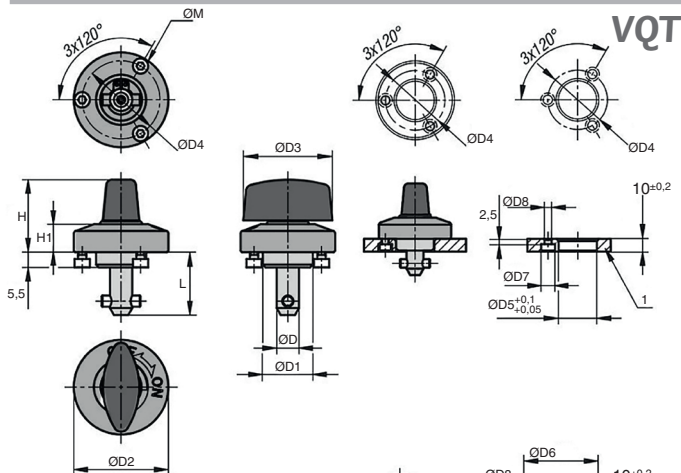

Example of use:
change the positions of the camera

DISCOUNTS

Qty	1+	4+	8+
Disc.	List	-5%	On request

Part number	ØD	L	ØD1	ØD2	ØD3	ØD4	ØD5	ØD6	ØD7	ØD8	T	T1	Price each 1 to 3
Plastic button													
VQT5-15/PA	5	15,5	14	25	20	21	14	26	4,4	2,4	6	6-10	47,70 €
VQT8-17/PA	8	17,0	18	34	32	28	18	35	6,5	3,4	6	6-14	49,06 €
VQT8-23/PA	8	23,0	18	34	32	28	18	35	6,5	3,4	12	12-20	49,06 €
Stainless steel button													
VQT5-15/SS	5	15,5	14	25	20	21	14	26	4,4	2,4	6	6-10	59,96 €
VQT8-17/SS	8	17,0	18	34	32	28	18	35	6,5	3,4	6	6-14	62,69 €
VQT8-23/SS	8	23,0	18	34	32	28	18	35	6,5	3,4	12	12-20	62,69 €

*Depending on availability - Dimensions in mm

Quarter-turn clamp lock - Clamping plate


VQTPLQ/P

Wall mounting

- **Clamping plate** for VQT quarter-turn lock
- Mounting for plate thickness 6 to 10mm.
- Materials:
Nickel-plated steel body
Stainless steel nut

Accessories

- VQT quarter-tour lock

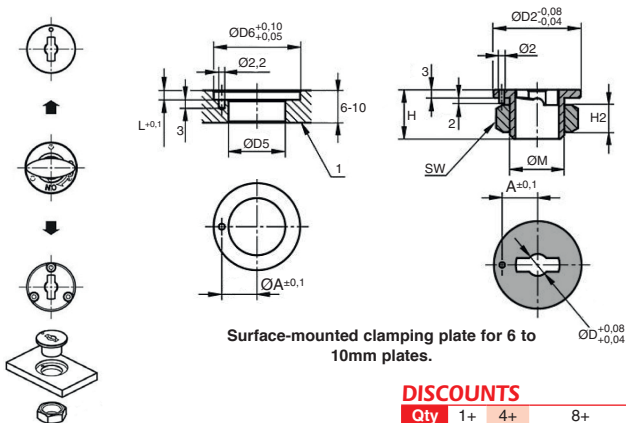

Surface-mounted clamping plate for 6 to 10mm plates.

DISCOUNTS

Qty	1+	4+	8+
Disc.	List	-5%	On request

Part number	ØD	ØD2	ØD4	A	M	H2	SW
VQT5-PLQ/P	5	25	21	10,5	M14X1,5	8	22
VQT8-PLQ/P	8	32	26	13,0	M20X1,5	10	30

Part number	H	H1	ØD5	ØD6	L	Price each
VQT5-PLQ/P	16	4,5	15	25	3,5	1 to 3 47,70 €
VQT8-PLQ/P	18	5,5	21	32	3,5	49,06 €

*Depending on availability - Dimensions in mm

Quarter-turn clamp lock - Clamping plate

Flush mounting

VQTPLQ/N


- **Clamping plate for VQT quarter-turn lock**
- Mounting for plate thickness over 10mm.
- Materials:
Nickel-plated steel body

Infos

- The M2 or M3 fixing screws are supplied

Accessories

- VQT quarter-turn lock

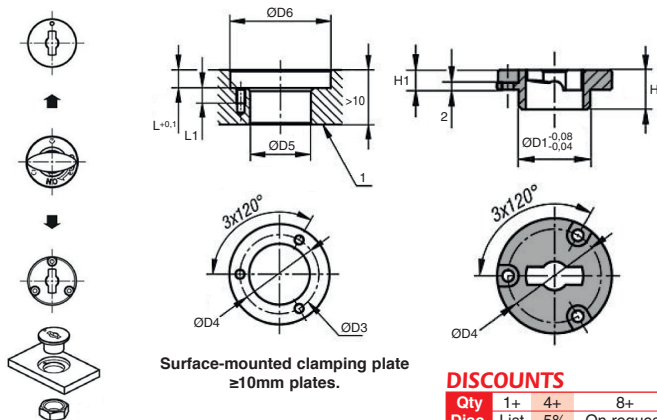

DISCOUNTS


Qty	1+	4+	8+
Disc.	List	-5%	On request

Part number	ØD	ØD1	ØD2	ØD4	H2	SW
VQT5-PLQ/N	5	14	25	21	8	22
VQT8-PLQ/N	8	20	32	26	10	30

Part number	H	H1	ØD3 for screw DIN912				L	L1	Price each 1 to 3
			ØD5	ØD6	ØD7	ØD8			
VQT5-PLQ/N	9	4,5	M2	14	26	5	4		21,39 €
VQT8-PLQ/N	11	5,5	M3	20	33	6	5		22,73 €

*Depending on availability - Dimensions in mm

 Our other products



RDE-W
Sealing washer
Hygienic Usit®,
Stainless steel - White
EPDM




SRG
Adjustable latch
clamp with strike
plate, Stroke from
117,4mm to 128mm



BAP
Plastic clamping
collar, Ø10 - Ø20



DILC
Indexing plunger with
cam, with cam

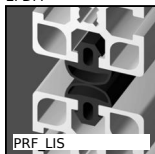

PRF LIS
Door seal for
aluminium profile,
Black NBR



CHMR75
Worm and wheel gear
reducer, up to 298
Nm



RURt
Swivel castor with
central hole,
Polyurethane -
Aluminium rim (Free



BAC105
Storage bin, 8mm



VML
Stainless steel
hexagonal headed
thumb screw, Male



SVG
Adjustable latch
clamp with strike
plate, Stroke from



PPF
Indexing plunger with
flange, with drilled
flange



SH2
Parallel axis helical
gear, Machined plastic
(delrin)

Complementary products



VQTplqn
Quarter-turn clamp
lock - Clamping plate,
Flush mounting



VQT
Quarter-turn clamp
lock, Plastic or
stainless steel button