

# Lifting ring, for welding


## Dual bearings

**RUD** VRBS

- 2 mounting points for a better distribution of applied forces
- High dynamic and static strength
- Low profile
- SWL clearly marked
- Mounts manufactured from S355J2+N steel alloy
- Corrosion resistant epoxy coating

### Info.

- Ring should not be welded
- Welding to be carried out by suitably qualified personnel
- Ring profile conforms to the welding requirements of DIN18800 (welding instructions supplied with the product)
- Position of welding positions (closed, HV) ensures corrosion resistance and renders the ring suitable for use outside.

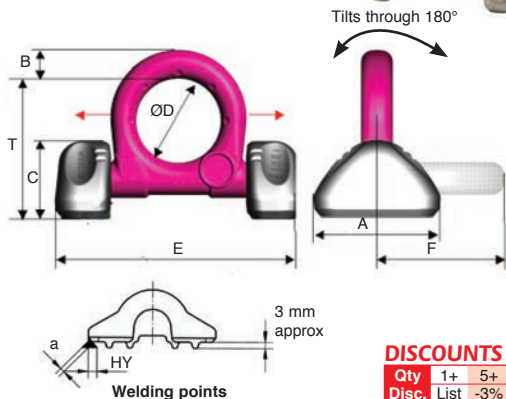

### DISCOUNTS

Qty	1+	5+	10+	15+
Disc.	List	-3%	-6%	On request

Part number	SWL (t)	A	B	C	ØD	E	F	T	Weight (kg)	Weld size	Length	Price each 1 to 4
VRBS-4	4,0	62	14	28	48	135	71	65	0,9	HY 4 + a 3	2 x 130 mm	42,40 €
VRBS-6	6,7	88	20	39	60	170	92	84	2,1	HY 5,5 + a 3	2 x 170 mm	74,47 €
VRBS-10	10,0	100	22	46	65	195	100	95	3,0	HY 6 + a 4	2 x 190 mm	124,86 €
VRBS-16	16,0	130	30	57	90	263	134	127	6,9	HY 8,5 + a 3	2 x 250 mm	224,71 €
VRBS-31	31,5	160	42	79	130	375	195	178	19,0	HY 18 + a 4	2 x 365 mm	545,12 €

Dimensions in mm

## Our other products



AKN

Bellows coupling  
Gerwah®, from 22 to  
180Nm



ERT

Sliding nut, For T slot



PSG05HC

Skive hobbed spur  
gears - precision  
range, Case hardened  
steel 20NCD2



NRV

Sensor support,  
Orthogonal support  
clamp



MBEX

Manual gearbox,  
Hexagonal ended  
handle



OP7

Numerical counter (No  
of turns), 5 numbers



CHAE4060PA

Decorative hinges,  
Polyamide



BOX-CSss

Hose clamp, Box set  
of stainless steel hose  
clamp



BAC105

Storage bin, 8mm



HLA28

Right angle bevel  
gearbox, Up to  
182Nm



MRA

Quick link, Steel



CHM110

Worm and wheel  
gearbox, up to 980  
Nm

## Complementary products



VLBS

Lifting ring, Folding -  
for welding



ASH

Hoist ring, for straight  
lifts - for welding



ASL

Hoist ring, for 45° lifts  
- for welding



PPS

Lifting ring, Universal  
threaded