

Retaining catch, single sided

VRC1

Indexed 4 x 90°

Adjustable retaining catch

- To be used for door locking, drawers and as handling aid.

- Material :



Body :

Die cast zinc, black similar to RAL 9005

Die cast zinc, silver similar to RAL 9006

Internal pieces : Sintered metal

Screw : A2 stainless steel (ISO 10642)

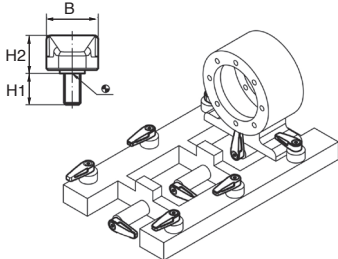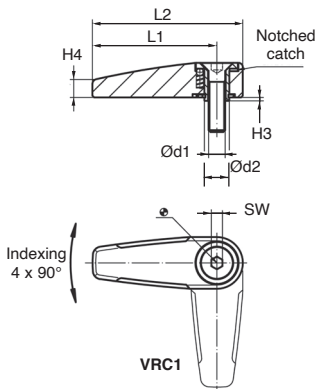

Typical application

IN STOCK*
Otherwise contact us

DISCOUNTS

Qty	1+	6+	20+
Disc.	List	-10%	On request

Part number	Colour	Ød1	Ød2	L1	L2	B	H1	H2	H3	H4	SW	Weight (g)	Price each 1 to 5
VRC1-M6/A	Silver	M6	9	45	55	19,0	12	13,3	0,8	6,5	4	59	20,13 €
VRC1-M8/A	Silver	M8	14	65	78	25,2	14	15,8	0,8	9,0	5	136	25,18 €
VRC1-M6/N	Black	M6	9	45	55	19,0	12	13,3	0,8	6,5	4	59	20,13 €
VRC1-M8/N	Black	M8	14	65	78	25,2	14	15,8	0,8	9,0	5	136	25,18 €

*Depending on availability - Dimensions in mm

Retaining catch, dual sided

Indexed 4 x 90°

VRC2

Adjustable retaining catch

- To be used for door locking, drawers and as handling aid.

- Material :


Body :

Die cast zinc, black similar to RAL 9005


Die cast zinc, silver similar to RAL 9006

Internal pieces : Sintered metal

Screw : A2 stainless steel (ISO 10642)

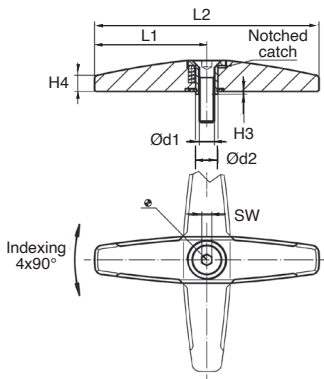

VRC2

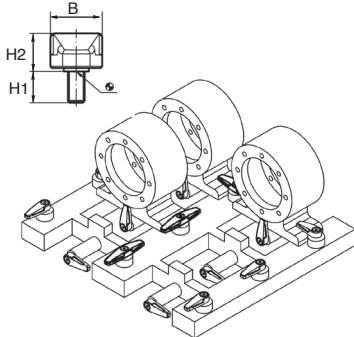

Typical application



DISCOUNTS

Qty	1+	6+	20+
Disc.	List	-10%	On request

Part number	Colour	Ød1	Ød2	L1	L2	B	H1	H2	H3	H4	SW	Weight (g)	Price each 1 to 5
VRC2-M6/A	Silver	M6	9	45	90	19,0	12	13,3	0,8	6,5	4	93	22,53 €
VRC2-M8/A	Silver	M8	14	65	130	25,2	14	15,8	0,8	9,0	5	220	29,13 €
VRC2-M6/N	Black	M6	9	45	90	19,0	12	13,3	0,8	6,5	4	93	22,53 €
VRC2-M8/N	Black	M8	14	65	130	25,2	14	15,8	0,8	9,0	5	220	29,13 €

*Depending on availability - Dimensions in mm


Our other products



RFV63
Stainless steel worm and wheel gearbox, up to 152 Nm



 
LRR
Spring loaded latch, Spring loaded latch



GBMf
Flanged leadscrew nut, Flanged nut - Multiple starts



 SH3
Parallel axis helical gear, Steel 20NCD2



G1
Steel spur gear, Steel 20NCD2



PW_PWG1
Worm - precision range, Steel



MFBSC
Stainless steel flexible bellows coupling, Stainless steel - with cl...



RMSA
Adjustable shock-absorber, Adjustable



BAP
Plastic clamping collar, $\varnothing 10 - \varnothing 20$



KB_UU
Closed linear precision bearing, Precision - steel



PGNT
Thermoplastic T handle, With threaded insert



OP2
Mechanical digital position indicator, 3 numbers

Complementary products



VRC2
Retaining clamp, dual sided, Dual sided