

# Retaining catch, single sided

## VRC1

## Indexed 4 x 90°

### Adjustable retaining catch

- To be used for door locking, drawers and as handling aid.

- Material :


 

Body :

Die cast zinc, black similar to RAL 9005

Die cast zinc, silver similar to RAL 9006

Internal pieces : Sintered metal

Screw : A2 stainless steel (ISO 10642)

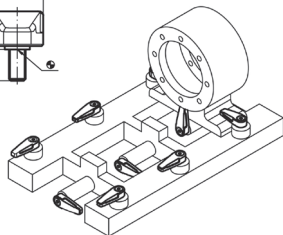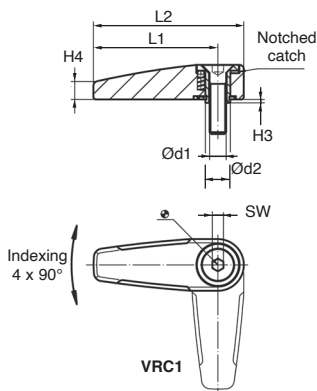

Typical application



### DISCOUNTS

Qty	1+	6+	20+
Disc.	List	-10%	On request

Part number	Colour	Ød1	Ød2	L1	L2	B	H1	H2	H3	H4	SW	Weight (g)	Price each 1 to 5
VRC1-M6/A	Silver	M6	9	45	55	19,0	12	13,3	0,8	6,5	4	59	20,13 €
VRC1-M8/A	Silver	M8	14	65	78	25,2	14	15,8	0,8	9,0	5	136	25,18 €
VRC1-M6/N	Black	M6	9	45	55	19,0	12	13,3	0,8	6,5	4	59	20,13 €
VRC1-M8/N	Black	M8	14	65	78	25,2	14	15,8	0,8	9,0	5	136	25,18 €

\*Depending on availability - Dimensions in mm

# Retaining catch, dual sided

Indexed 4 x 90°

VRC2

## Adjustable retaining catch

- To be used for door locking, drawers and as handling aid.

- Material :


Body :

Die cast zinc, black similar to RAL 9005


Die cast zinc, silver similar to RAL 9006

Internal pieces : Sintered metal

Screw : A2 stainless steel (ISO 10642)

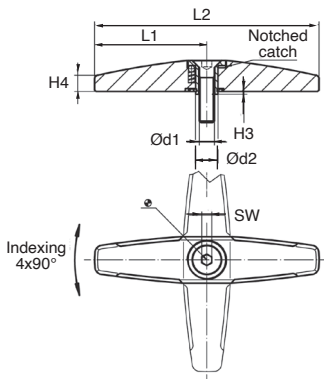

VRC2

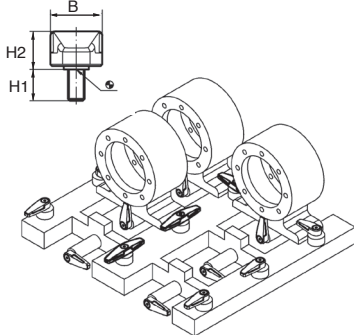

Typical application



## DISCOUNTS

Qty	1+	6+	20+
Disc.	List	-10%	On request

Part number	Colour	Ød1	Ød2	L1	L2	B	H1	H2	H3	H4	SW	Weight (g)	Price each 1 to 5
VRC2-M6/A	Silver	M6	9	45	90	19,0	12	13,3	0,8	6,5	4	93	22,53 €
VRC2-M8/A	Silver	M8	14	65	130	25,2	14	15,8	0,8	9,0	5	220	29,13 €
VRC2-M6/N	Black	M6	9	45	90	19,0	12	13,3	0,8	6,5	4	93	22,53 €
VRC2-M8/N	Black	M8	14	65	130	25,2	14	15,8	0,8	9,0	5	220	29,13 €

\*Depending on availability - Dimensions in mm

## Our other products




DOG316

Motor-gearbox 12V and 24V DC, from 1.5 to 2 Nm



SCR

Suction cup threaded insert, Adaptor for insert

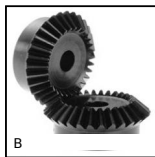

B

Steel bevel gear, 1:1



PSG05

Spur gear - precision range, Pre-hardened Steel 35NCD6



CHT

Asynchronous AC Motor, 0.18 to 0.55kW



PSP

Support profile, Panel support



PRES

Manual workbench press accessory for PRES-3HR end PRES-4HR, Micromet...



BLH40

Right angled gearbox, from 3 to 10.30 Nm



HAR9

Captive C washer, DIN 6371



MAX26

Motor-gearbox 12V and 24V DC, from 0,075 to 0,6Nm



SER69K-CLE

Quarter turn latch for the food industry, Stainless steel key



ACLBMC

Detector support for aluminium profile, Sensor holder

## Complementary products



VRC1

Retaining clamp, single sided, Single sided