

Retaining catch, single sided

VRC1

Indexed 4 x 90°

Adjustable retaining catch

- To be used for door locking, drawers and as handling aid.

- Material :


 

Body :

Die cast zinc, black similar to RAL 9005

Die cast zinc, silver similar to RAL 9006

Internal pieces : Sintered metal

Screw : A2 stainless steel (ISO 10642)

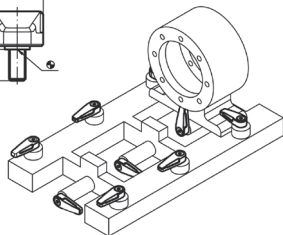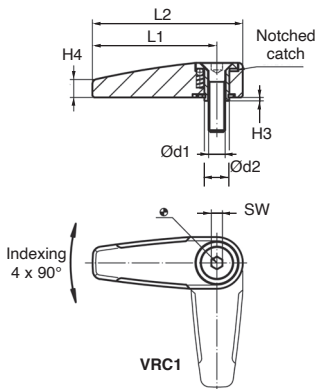

Typical application



DISCOUNTS

Qty	1+	6+	20+
Disc.	List	-10%	On request

Part number	Colour	Ød1	Ød2	L1	L2	B	H1	H2	H3	H4	SW	Weight (g)	Price each 1 to 5
VRC1-M6/A	Silver	M6	9	45	55	19,0	12	13,3	0,8	6,5	4	59	20,13 €
VRC1-M8/A	Silver	M8	14	65	78	25,2	14	15,8	0,8	9,0	5	136	25,18 €
VRC1-M6/N	Black	M6	9	45	55	19,0	12	13,3	0,8	6,5	4	59	20,13 €
VRC1-M8/N	Black	M8	14	65	78	25,2	14	15,8	0,8	9,0	5	136	25,18 €

*Depending on availability - Dimensions in mm

Retaining catch, dual sided

Indexed 4 x 90°

VRC2

Adjustable retaining catch

- To be used for door locking, drawers and as handling aid.

- Material :


Body :

Die cast zinc, black similar to RAL 9005


Die cast zinc, silver similar to RAL 9006

Internal pieces : Sintered metal

Screw : A2 stainless steel (ISO 10642)

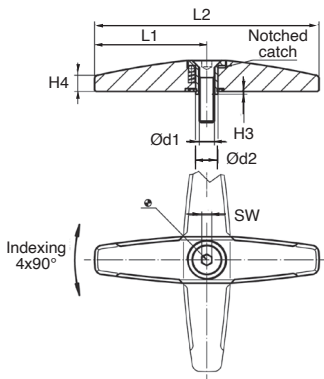

VRC2

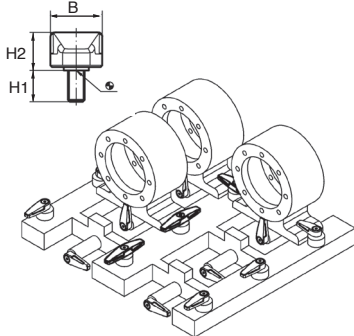

Typical application



DISCOUNTS

Qty	1+	6+	20+
Disc.	List	-10%	On request

Part number	Colour	Ød1	Ød2	L1	L2	B	H1	H2	H3	H4	SW	Weight (g)	Price each 1 to 5
VRC2-M6/A	Silver	M6	9	45	90	19,0	12	13,3	0,8	6,5	4	93	22,53 €
VRC2-M8/A	Silver	M8	14	65	130	25,2	14	15,8	0,8	9,0	5	220	29,13 €
VRC2-M6/N	Black	M6	9	45	90	19,0	12	13,3	0,8	6,5	4	93	22,53 €
VRC2-M8/N	Black	M8	14	65	130	25,2	14	15,8	0,8	9,0	5	220	29,13 €

*Depending on availability - Dimensions in mm

Our other products



CHB

Worm and wheel gear reducer, up to 22 Nm



CHT

Asynchronous AC Motor, 0.18 to 0.55kW




PCS375S

Chain sprocket - Stainless steel, 9.525 (DIN 06B-1)



PR105

Articulated foot Ø103, Ø 103

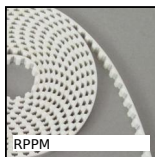

RPPM

RPP type belt per metre, RPP8 Steel cored polyurethane



ACLEFS

Floor anchor for aluminium profile, Adjustable



GPLSS

Brush, stainless steel



SH0

Parallel axis helical gear, Steel 20NCD2



RFK58C

Hypoid gearbox - Stainless steel, up to 500 Nm



TBD

Manual leadscrew table with opposing threads, 5kg



SBS_L

Chain link, Stainless steel



CHTRB

Single and dual output gearboxes, Up to 53,1 Nm

Complementary products



VRC1

Retaining clamp, single sided, Single sided